

5Seconds™

5 Second™ Ultimate Series High Velocity Hand Dryer 1000W



Description

5 Seconds™ is the original high-speed, energy-efficient hand dryer that dries hands within 10 seconds. Fastest, most powerful automatic dryers in the business. They really work! 5Seconds™ Ultimate Series High Velocity Hand Dryer is ideal for public restrooms in schools, offices, theatres and more. Hand dryer features an infrared sensor for sanitary touch-free operation. Stainless steel cover with satin finish. UL Listed ADA compliant.


Specifications

Brand	5 Seconds
SKU# (Brushed)	111012
SKU# (White)	111013
Voltage	120V 60Hz, 8.3A, 1000W
Air Temperature	40°C [104°F]
Air Velocity	100M/Seconds [328 FT/S]
Drying Time	10 to 12 Seconds
Protection Level	IP23
Electrical Isolation	Class I
Sensor Range	5-15CM
Dimensions	W11.2 x D4 x H12.6 Inches
Material	Stainless Steel 304
Motor Power	35000RPM, 600W [0.80HP]
1- Visible Service Blue LED	
2- 60 Seconds Automatic Shut Off	

Feature

- High speed and long-lasting ECO friendly product
- Dry hands completely in 8 - 10 seconds and 3times faster
- Maintenance-free, hard-wired
- Energy efficient
- 95% Cost Savings vs. Paper Towels
- The most HYGIENIC drying solution and best hand dryer
- 80% Less Energy Than Conventional Hand Dryers
- 8-10 Second Dry Time
- Externally Visible Service LED
- Saves Time, Money and the Environment
- 60 Seconds Automatic Shut Off
- Coarse Particulate Filter

Dimensions

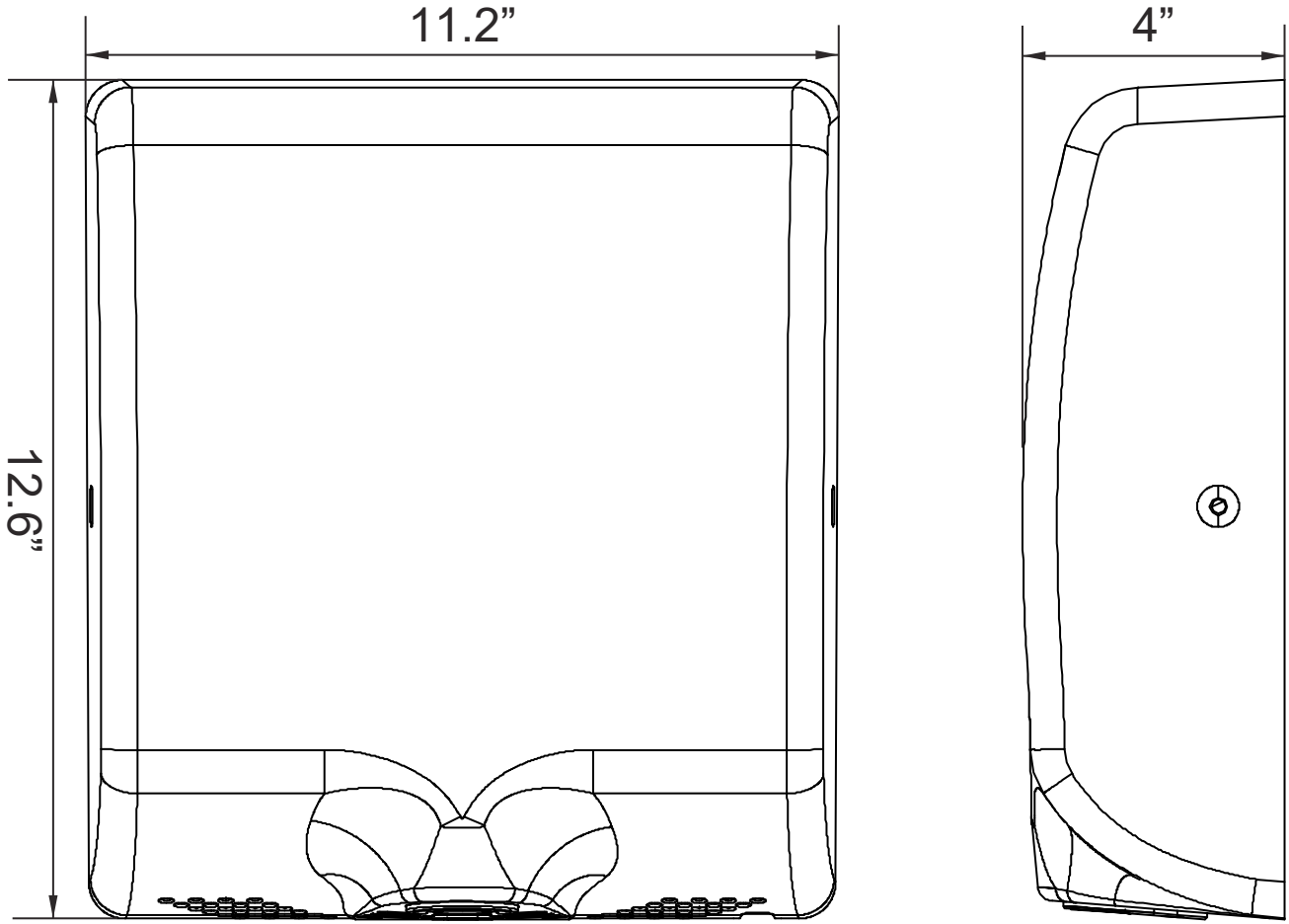

Automatic hands ON/OFF by infrared sensor



100 Meter/seconds speed
10- 12 Seconds drying time
60 Seconds auto shut off



Externally visible service blue LED guides hands to air flow



High Speed Motor



Dual protection heater by Thermostat & Thermal Cutoff



Cover right grounding



Fireproof key plastic parts & stainless steel cover



Convenient plug in feature
Optional hardwire installation



Easy maintenance
Easy wall surface mounted
Anti-theft lockable



Customized heater ON/OFF switch



Customized speed & sound control from 300 W - 1800 W



4" [10CM] depth ADA-compliant



Customized intelligent heater off if ambient temperature is more than 25°C[77°F]



Customized HEPA & coarse particulate filter at air inlet



4" [10 CM] depth Behind mirror hand dryer