

ART REVISION #: 2


ART REVISION DATE: 04/07/2015

FINAL ART DATE: 04/07/2015


US SPEC #: A01-1116-1463 A

FRONT PANEL: 130 X 145 mm

US PART #: 3235 826664 01

PRODUCTION NOTES:	ARTWORK SPECIFICATIONS:	
<ul style="list-style-type: none"> <li>This proof indicates approximate color only!</li> <li>All colors print 100% unless otherwise indicated</li> <li>All structure and holding lines do not print unless otherwise indicated.</li> <li>This is prepared as a color digital mechanical, no traps have been made.</li> <li>All trapping is the responsibility of the engraver and/or separator and/or printer.</li> </ul>	<p>Date: 04/07/2015    Project Name: PAR38    Brand: Philips LED    Product Name/Description: 11PAR38 F25 830 ND 120V    File Name: 457993_11PAR38_F25_830_ND_3235 826664 01.ai</p> <p>Component Type: Folding Box    Die Line No.: 01160914    Product Number:    Artwork Program: AI C56    Manufacturing Site: China</p> <p>Version No.: 2    Print Method:    Number of Colors: 1 color (black ink)    Bar Code No.: 0 46677 45799 0    Languages: English</p> <p><b>COLORS:</b> Note: All colors for reference only; printer to use pre-approved color drawdowns when printing.</p> <p><b>MATERIALS &amp; COATINGS:</b> Note: Refer to applicable Component (PC) Specification for exact details/requirements on substrates and coatings/varnishes when printing.</p> <p>Varnishes/Special Coatings:    Graphic Specialist: ES    Packaging Engineer: AH    Agency: ES</p>	
	PRINT SPECIFICATIONS:	
	<p><b>COLORS:</b>  Black</p>	<p><b>FONTS:</b> Gill Sans Regular, Gill Sans Bold, Gill Sans Light, Gill Sans Italic, Gill Sans Bold Condensed, Arial Bold, Arial Regular</p>
	<b>PHILIPS</b>	

Limited Warranty Insert to be printed on separate B&W package insert.

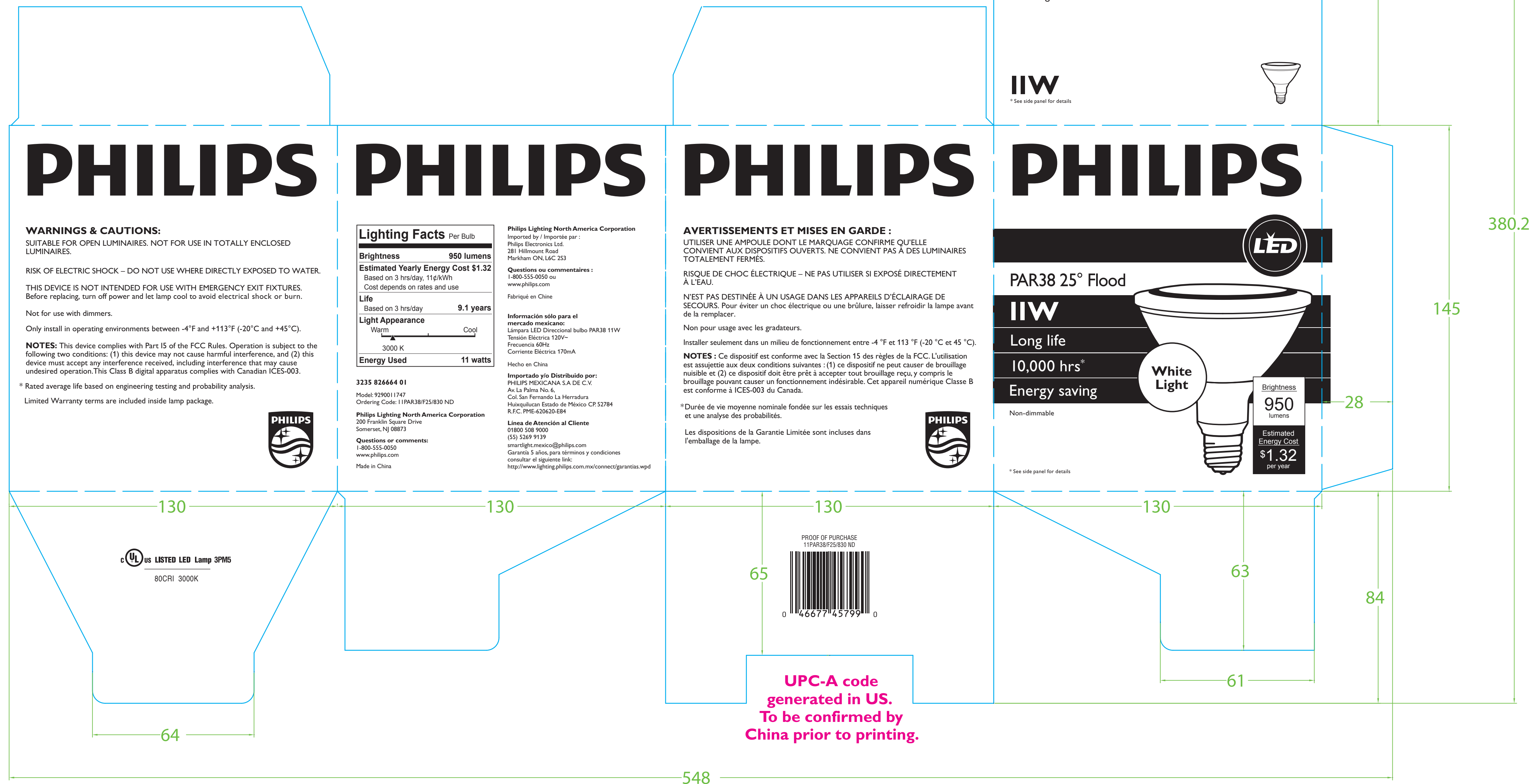

**PHILIPS** **PHILIPS** **PHILIPS** **PHILIPS**

**PAR38 White Flood 10,000hrs\***  
Model: 9290011747  
Ordering Code: 11PAR38/F25/830 ND

**IIW**  
\* See side panel for details

**PAR38 25° Flood**  
**IIW**  
Long life  
10,000 hrs\*  
Energy saving  
Non-dimmable

**White Light**  
Brightness: 950 lumens  
Estimated Energy Cost: \$1.32 per year

**WARNINGS & CAUTIONS:**  
SUITABLE FOR OPEN LUMINAIRES. NOT FOR USE IN TOTALLY ENCLOSED LUMINAIRES.  
RISK OF ELECTRIC SHOCK – DO NOT USE WHERE DIRECTLY EXPOSED TO WATER.  
THIS DEVICE IS NOT INTENDED FOR USE WITH EMERGENCY EXIT FIXTURES. Before replacing, turn off power and let lamp cool to avoid electrical shock or burn.  
Not for use with dimmers.  
Only install in operating environments between -4°F and +113°F (-20°C and +45°C).  
**NOTES:** This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) this device may not cause harmful interference, and (2) this device must accept any interference received, including interference that may cause undesired operation. This Class B digital apparatus complies with Canadian ICES-003.  
\* Rated average life based on engineering testing and probability analysis.  
Limited Warranty terms are included inside lamp package.

**Lighting Facts** Per Bulb  
Brightness: 950 lumens  
Estimated Yearly Energy Cost \$1.32  
Based on 3 hrs/day, 11¢/kWh  
Cost depends on rates and use  
Life: 9.1 years  
Based on 3 hrs/day  
Light Appearance: Warm to Cool  
Energy Used: 11 watts

Philips Lighting North America Corporation  
Imported by / Importée par :  
Philips Electronics Ltd.  
291 Hillhouse Road  
Markham, ON, L3C 2S3  
Questions ou commentaires :  
1-800-555-0050 ou  
www.philips.com  
Fabriqué en Chine  
Información sólo para el mercado mexicano:  
Lámpara LED DireccionaL bulbo PAR38 11W  
Tensión Eléctrica 120V~  
Frecuencia 60Hz  
Corriente Eléctrica 170mA  
Hecho en China  
Importado y/o Distribuido por:  
PHILIPS MEXICANA S.A DE C.V.  
Av. La Palma No. 6,  
Col. San Fernando La Herradura  
Huixquilucan Estado de México CP 52784  
R.F.C. PME-620620-E84  
Línea de Atención al Cliente  
91800 508 9000  
(55) 5269 9139  
amarright@mexico.philips.com  
Garantía: 5 años, para términos y condiciones  
consultar el siguiente link:  
http://www.lighting.philips.com.mx/connect/garantias.wpd

**AVERTISSEMENTS ET MISES EN GARDE :**  
UTILISER UNE AMPOULE DONT LE MARQUAGE CONFIRME QUELLE CONVIENT AUX DISPOSITIFS OUVERTS. NE CONVIENT PAS À DES LUMINAIRES TOTALEMENT FERMÉS.  
RISQUE DE CHOC ÉLECTRIQUE – NE PAS UTILISER SI EXPOSÉ DIRECTEMENT À L'EAU.  
N'EST PAS DESTINÉE À UN USAGE DANS LES APPAREILS D'ÉCLAIRAGE DE SECOURS. Pour éviter un choc électrique ou une brûlure, laisser refroidir la lampe avant de la remplacer.  
Non pour usage avec les gradateurs.  
Installer seulement dans un milieu de fonctionnement entre -4 °F et 113 °F (-20 °C et 45 °C).  
**NOTES :** Ce dispositif est conforme avec la Section 15 des règles de la FCC. L'utilisation est assujettie aux deux conditions suivantes : (1) ce dispositif ne peut causer de brouillage nuisible et (2) ce dispositif doit être prêt à accepter tout brouillage reçu, y compris le brouillage pouvant causer un fonctionnement indésirable. Cet appareil numérique Classe B est conforme à ICES-003 du Canada.  
\*Durée de vie moyenne nominale fondée sur les essais techniques et une analyse des probabilités.  
Les dispositions de la Garantie Limitée sont incluses dans l'emballage de la lampe.

UPC-A code generated in US. To be confirmed by China prior to printing.