



PHILIPS LIGHTING			
Brand	Philips		
Product Family	LED SPOT ND		
Shape	PAR38		
Wattage	13.5		
Template Ref.	Basic 0008		
SGS number	5273727		
I2-NC.NBR	323583022001		
Masterdrawing	324164804431		
CRC Ref.	202US		
Barcode No.	046677469108		
Operator(s)	daryl.hollier		
VERSION No.	v1		
Date in	18/12/2017		
Date amended	20-Dec-17		
Cyan	Magenta	Yellow	Black
Guides	Diecut		
Date Check			
<input type="checkbox"/> Check briefing Traffic			
Artwork document			
<input type="checkbox"/> Legend	<input type="checkbox"/> Number of colors		
<input type="checkbox"/> 12NC	<input type="checkbox"/> Trapping/Bleed		
<input type="checkbox"/> Barcode	<input type="checkbox"/> Images hires		
<input type="checkbox"/> Diecut	<input type="checkbox"/> Jobsizes		
Approval			
<input type="checkbox"/> QC Lithographer SGS Production			
<input type="checkbox"/> Product Manager			
<input type="checkbox"/> Traffic Manager SGS Production			



Party LED Bulb

Great for parties, holidays and special occasions.

*** LIMITED WARRANTY:**
Guaranteed to last 3 years based on up to 3 hours usage per day. For limited warranty details and restrictions visit: www.philips.com/consumerwarranties or call or write to address on package.

WARNINGS AND CAUTIONS:
Suitable for use in enclosed luminaires. Suitable for wet locations. Not suitable for use with dimmers. This device is not intended for use with emergency exit fixtures or emergency lights. Before replacing, turn off power and let lamp cool to avoid electrical shock or burn. Only install in operating environments between -4°F and +113°F (-20°C and +45°C).

NOTES:
This device complies with Part 15 of the FCC Rules. Operation is subject to the following two conditions: (1) This device may not cause harmful interference, and (2) This device must accept any interference received, including interference that may cause undesired operation. Any changes or modifications not expressly approved by the party responsible for compliance could void the user's authority to operate the equipment. This Class B digital apparatus complies with Canadian ICES-005.


***LED lifetime** means the length of time (in years) until half of the LED light sources maintain at least 70% of their initial lumen output (850, L70), where the lamp is used on average 3 hours/day.



PROOF OF PURCHASE:
13.5PAR38/PER/RED/ND/U/LW/G/120V
3235 830220 01
Model: 9290013068
© Philips Lighting Holding BV, 2017
Made in China



Party LED

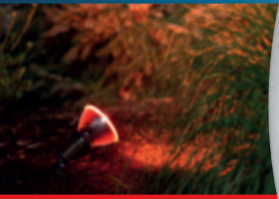

Red light

13.5w LED

Indoor/Outdoor
PAR38 Flood

3 Year Warranty¹

Light up with color



Philips Lighting North America Corporation
200 Franklin Square Drive
Somerset, NJ 08873 USA
Questions or Comments:
1-800-255-0050
www.philips.com

Información sólo para el mercado Mexicano
Lámpara LED Direccional PAR38/13.5W
Tensión Eléctrica 120V~
Frecuencia 60Hz
Corriente Eléctrica RMSA
Vida Nominal: 10.950 h
Contenido 1 pieza(s)
Hecho en China

Importada y/o Distribuida por:
PHILIPS MEXICANA S.A DE C.V.
Av. La Palma No. 6 Col.
San Fernando La Herradura
Huatquillan Estado de México CP. 52784
R.F.C. PHM-200209-E88
Línea de Atención al Cliente
01800 508 9000 | (55) 5269 9139
smartlight@mexico.philips.com

Garantía 3 años, para términos y condiciones consultar el siguiente link:
<http://www.lighting.philips.com.mx/conect/garantias.wpd>

