

MAN & MACHINE

Really Cool Touch

Medical Grade™

Terminally Cleanable Keyboards w/ Touchpad



Featuring

Tru-Lock



Washable at Workstation

Terminally



Withstands Submersion in 1:10 Bleach Solution

100% Quality



For Exceptional Return-on-Investment

Sani-Type



Great Tactile Feel Single or Double Gloved

Born-in-USA




Engineered, Manufactured & Serviced

Really Cool Touch Details & Optional Private Labeling

 Optional Hospital Name & Logo Here

MAN & MACHINE

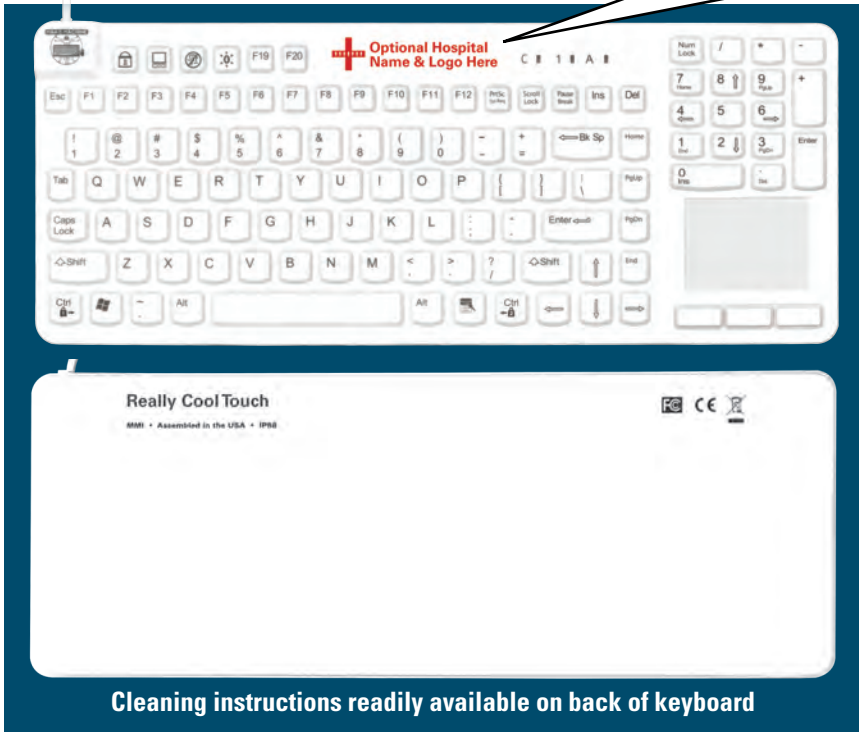

Cleaning instructions readily available on back of keyboard




Low profile keys make cleaning easier and a pleasure for typing



Fully sealed and seamless




Hygienic white keyboard lets you see bioburden

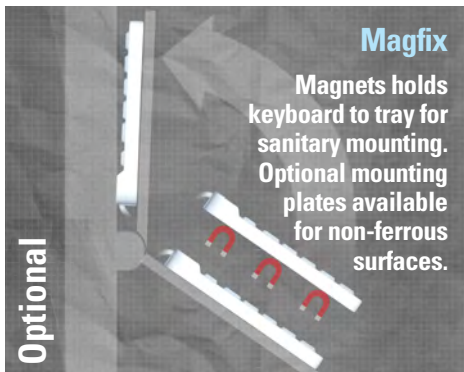

Magfix

Magnets holds keyboard to tray for sanitary mounting. Optional mounting plates available for non-ferrous surfaces.

Optional

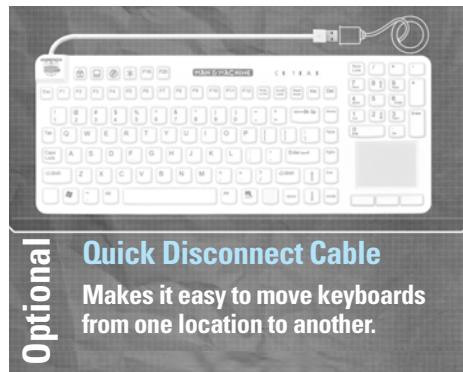

Quick Disconnect Cable

Makes it easy to move keyboards from one location to another.

Optional



Multi-Level Backlight

Allows light levels to be easily adjusted for any needed key illumination.

Optional

Features

- Sealed, waterproof, immersible
- 100% Silicone rubber skin, no latex
- Tru-Lock - Keys lock for workstation disinfection
- May be terminally cleaned
- Quick disconnect available
- Excellent tactile feedback w/ gloves
- No moving parts, no mechanical failure
- Clean with any EPA-certified disinfectant
- Standard key pitch
- 2-year warranty w/ limited lifetime warranty available

Specifications

- Size: 15 x 5.9 x 0.6 in (38.1 cm x 15 cm x 1.5 cm)
- Weight: 1.9 lb (840 g)
- Cable Length: 72 in (1.83 m)
- Storage temperature: -20° to 70°C (-4° to 158°F)
- Operating temperature: 0° to 70°C (32° to 158°F)
- Power Consumption: 26mA (Max)
300mA (backlighting)
- Platform: Windows and Mac
- Layout: Includes numeric keypad and 12 Function keys
- Interface: USB
- Color: Black or Hygienic White
- Resistance: IP68
- Compliance: CE, FCC, EN-60601

Color Choices



Hygienic White



Black



info@mmimd.com
www.man-machine.com
(301) 341-4900

