


8U 19" Wall Mount Network Rack - 12" Deep 2 Post Open Frame Server Room Rack for Data/AV/IT/Computer Equipment/Patch Panel with Cage Nuts & Screws 135lb Capacity, Black

Product ID: RK812WALLO

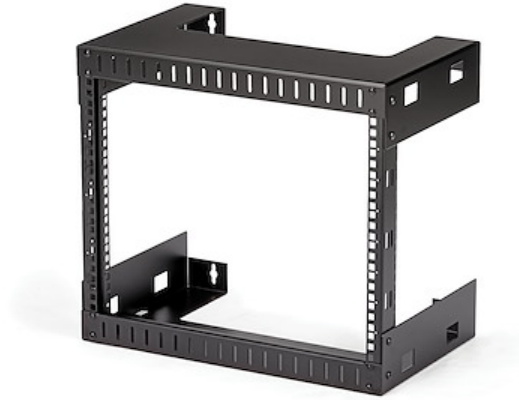

The RK812WALLO 8U Open Frame Wall Mount Equipment Rack (12in Depth) is a high quality, low cost relay rack that is easy to assemble and install into any environment. The rack can be wallmounted or installed as a free standing storage solution. This TAA compliant product adheres to the requirements of the US Federal Trade Agreements Act (TAA), allowing government GSA Schedule purchases.

Able to accommodate common networking, audio-video and telecom equipment, the open rack offers a depth of 12in; the wall mounts are positioned 16in apart (center to center), making it suitable for mounting on virtually any wall surface, based on North American wall frame stud spacing standards.

This 8U rack can be mounted to the wall in a server room, office, or above a doorway, expanding your workspace and keeping your equipment easily accessible.


Backed by a StarTech.com lifetime warranty.

Certifications, Reports and Compatibility

Applications

- Perfect for installing network switches out of the way and high up on a wall in a branch office, warehouse, or superstore location Ideal for small and medium businesses requiring small rack solutions dispersed throughout the organization
- Mounting Audio Video broadcast or distribution components

Features

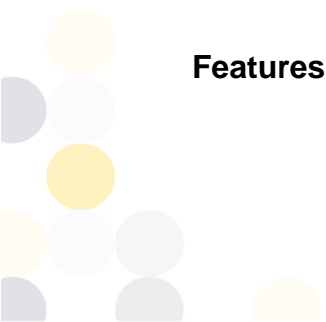

- **STURDY & CONVENIENT:** 8U 19" Open Frame wall mount network rack with 12" mounting depth is EIA/ECA-310 compatible & supports like patch panels, shelves and unmanaged switches
- **HEAVY DUTY:** This heavy duty 2 post open frame rack supports unobstructed airflow & is easy to install with a durable design made from SPCC cold-rolled steel with support for up to 135lbs of equipment
- **EASY ASSEMBLY:** The rack ships flat packed with ISTA-6 certified packaging to ensure complete and undamaged delivery and also features comprehensive assembly instructions
- **ACCESSORIES INCLUDED:** The wall mount server room/ computer/communication/AV/IT equipment rack includes a complete set of screws and cage nuts to securely mount all of your equipment in the rack
- **STARTECH.COM ADVANTAGE:** IT professionals' choice for over 30 years; our 2-post wall mount network racks backed for life by StarTech.com, including free 24/5 North America based multi-lingual tech support

Hardware

Warranty	Lifetime
Wallmountable	Yes
Rack Type	2-Post
Frame Type	Open Frame
U Height	8U
Special Features	Easy Assembly Wall-Mountable
Mounting Rail Profile	G-Shape
Mounting Hole Types	Square (For Cage Nut)
Industry Standards	EIA/ECA-310-E

Performance

Weight Capacity	176.8 lb [80 kg]
-----------------	------------------

Physical Characteristics

Color	Black
Construction Material	Steel

Product Measurements

Product Length	11.9 in [30.3 cm]
----------------	-------------------



Product Width	19.8 in [50.3 cm]
Product Height	17.8 in [45.1 cm]
Weight of Product	15.0 lb [6.8 kg]
Maximum Mounting Depth	11.8 in [30 cm]

Packaging Information

Flat Pack (Assembly Required)	Yes
Package Length	25.6 in [65.0 cm]
Package Width	21.8 in [55.4 cm]
Package Height	4.1 in [10.4 cm]
Shipping (Package) Weight	18.1 lb [8.2 kg]

What's in the Box

Included in Package	8U Rack
	M5 Screws
	M5 Cage Nuts
	Assembly Screws
	Installation Guide

****Product appearance and specifications are subject to change without notice.***

