

## 3 Port 2b 1a PCI 1394b FireWire Adapter Card with DV Editing Kit

**Product ID:** PCI1394B\_3



The PCI1394B\_3 3-Port PCI FireWire Adapter Card turns a PCI slot into 2 FireWire 800 (IEEE 1394b) ports and 1 FireWire 400 (IEEE 1394a) port - a cost-effective solution that lets you connect FireWire 800 devices, as well as older FireWire 400 devices to your desktop computer.

A versatile FireWire solution, the adapter card works in both 5v and 3.3v PCI slots and in 64-bit and 32-bit operating environments, making it easy to create a high-speed laptop digital media center, or connect demanding FireWire peripheral devices such as portable hard drives, DV camcorders, digital cameras and CD-RW/DVD-RW drives.

This high quality adapter card is designed to provide reliable FireWire 800 and FireWire 400 connections, delivering 800 Mbps and 400 Mbps data transfer rates respectively (a 64-bit PCI slot is required to achieve 800 Mbps data transfer rates).

The PCI1394B\_3 is backed by a StarTech.com lifetime warranty and free lifetime technical support.

## Certifications, Reports and Compatibility

### Applications

- Add a high-speed FireWire port to a desktop without any FireWire ports
- Connect a digital camera to a PCI/PCI-X enabled desktop to download photos and video
- Connect a high-speed external hard drive to an PCI/PCI-X enabled system

### Features

- Two FireWire 800 ports with support for data transfer rates up to 800 Mbps

- One FireWire 400 port with support for transfer rates up to 400 Mbps
- Complaint with IEEE 1394-1995, 2000, 1394b and OHCI 1.1 standards
- Compliant with PCI revision 2.2 specifications
- Compatible with 3.3V/5V, 32/64-bit PCI or PCI-X slots
- Plug-and-Play and Hot-Swap compatible
- Includes Video Editing kit: Ulead Video Studio SE and FireWire cable

---

#### Hardware

Warranty	Lifetime
Ports	3
Interface	FireWire 400 (1394a) FireWire 400 (1394a)
Bus Type	PCI / PCI-X (5 / 3.3V)
Card Type	Standard Profile
Industry Standards	PCI 2.2, OHCI, IEEE-1394B, IEEE-1394A, IEEE-1394
Chipset ID	Texas Instruments - 3AA651W

---

#### Performance

Maximum Data Transfer Rate	800 Mbps
----------------------------	----------

---

#### Connector(s)

Connector Type(s)	PCI / PCI-X (Universal 3.3 & 5V, 64-bit)
External Ports	FireWire 800 (9 pin, IEEE 1394b) FireWire 400 (6 pin, IEEE 1394a)


---

#### Software

OS Compatibility	Windows 2000, XP, Vista, 7, 8/8.1, 10 Mac OS 10.2.x Linux 2.4
------------------	---

---

#### Special Notes /

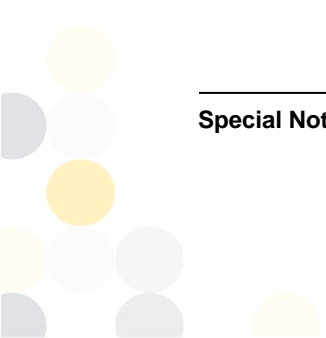

## Requirements

System and Cable Requirements      Unused PCI slot

The PCI1394B\_3 must be installed in a 64-bit PCI slot to achieve 800 Mbps data transfer rates. In a 32-bit PCI slot, the card defaults to 400 Mbps as the data transfer speed for all attached peripherals, including FireWire 800 devices

## Physical Characteristics

Material	Steel
Product Length	6.6 in [16.7 cm]
Product Width	0.7 in [18 mm]
Product Height	3.9 in [99 mm]
Weight of Product	3.1 oz [89 g]

## Packaging Information

Package Length	8.3 in [21.2 cm]
Package Width	1.6 in [40 mm]
Package Height	5.7 in [14.4 cm]
Shipping (Package) Weight	10.2 oz [290 g]

## What's in the Box

Included in Package	PCI FireWire Card
	FireWire Cable
	Software CD
	Instruction Manual

***\*Product appearance and specifications are subject to change without notice.***

