



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

Blaine LED Outdoor Sconce BLW Series

Features

This outdoor LED light is ideal for security and general lighting. Decorative metal accents. Provides lighting in residential, commercial, and hospitality applications. Fixture mounts to standard junction box (not included).

Construction

Standard mounting holes and hardware are included. Power supply connections must be made inside a junction box (not included).

Finish

Textured grey or textured bronze powder coated finish.

Diffuser

Diffuser is .100" thick matte white acrylic.

Electrical

Input 120-277 VAC / 60Hz.
Compatible with 0-10V dimmers.
Minimum starting temp -20°F.

Lamping

Fixture includes a LED modules capable of producing:
15-3/4" - 23W, 1800 source lumens
23" - 28W, 2800 source lumens
3000K (CCT). Rated for 50,000 Hrs. 90 CRI.


Certification

All fixtures are cETLus listed for wet locations.

Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 years from date of purchase.

**Specifications and dimensions
subject to change without notice.**

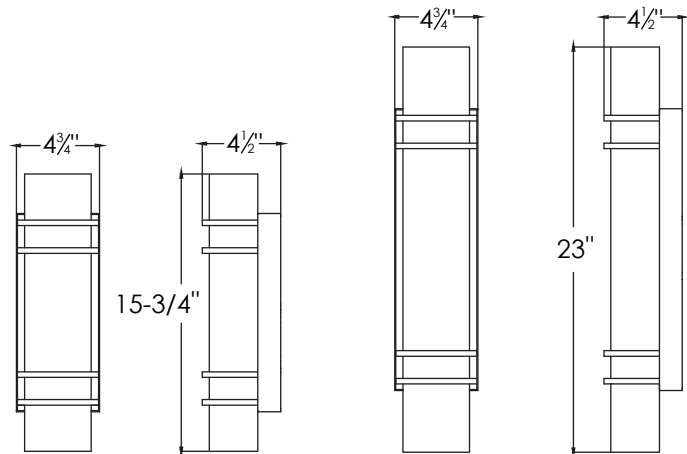

Ordering Information:

Textured Grey	Textured Bronze	LED	Source Lumens	CCT	H	W	D
BLW5161800L30MVTG	BLW5161800L30MVBZ	23W	1800	3000K	15-3/4"	4-3/4"	4-1/2"
BLW5232800L30MVTG	BLW5232800L30MVBZ	28W	2800	3000K	23"	4-3/4"	4-1/2"