



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

Dean LED Outdoor Ceiling DEAW Series

Features

Ideal use for general lighting in outdoor residential, commercial, and hospitality applications. Fixture can be mounted to a standard junction box (not included) on a wall or ceiling.

Construction

Polycarbonate housing and painted in weather resistant powder coating. Power supply connections must be made inside a junction box (not included).

Finish

Black, Textured Grey or Oil-Rubbed Bronze finish.

Diffuser

Frosted polycarbonate diffuser.

Electrical

Input 120 VAC / 60Hz.
Minimum starting temp -4° F/-20° C
Integrated photocell for dusk to dawn operation.

LED

Integrated LED modules capable of producing:
12W = 900 delivered lumens
20W = 1500 delivered lumens
Adjustable Choice 3000K, 4000K, 5000K (CCT).
Rated for 50,000 Hrs. 80 CRI.

Certification



All fixtures are cETLus listed for outdoor wet locations.
Title 24/JA8 Compliant
Ideal for coastal applications (IP65)

Warranty

5 Year Limited Warranty:

Restrictions apply based on location.

Specifications and dimensions
subject to change without notice.

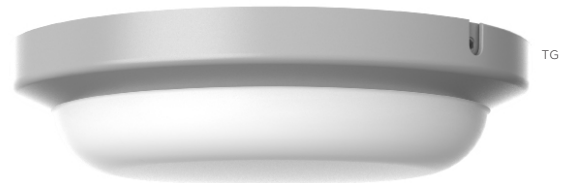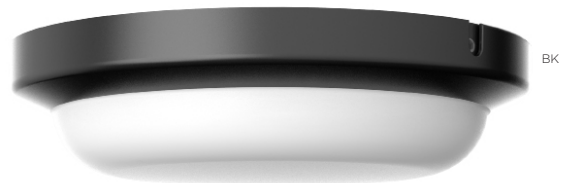

Ordering Information:

Black	Textured Grey	Oil-Rubbed Bronze	LED	Delivered Lumens	Adjustable CCT	DIA.	D
DEAW08LAJENBK	DEAW08LAJENTG	DEAW08LAJENBZ	12W	900	3000K/4000K/5000K	8"	2"
DEAW11LAJENBK	DEAW11LAJENTG	DEAW11LAJENBZ	20W	1500	3000K/4000K/5000K	11"	2-1/2"