



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

Edge Round LED Surface Mount Disc Light EGRF Series

Features

This ultra low profile design provides a dramatic look and features an edge-lit light panel construction. Products can be used in various applications including corridors, closets, bath, showers, hallway, kitchen and anywhere general lighting is needed.
Indoor use only - Wall or ceiling mount. Outdoor use only - Covered ceiling mount.



Construction

Edge-lit technology housing is injection molded with aluminum backplate.
Snap-in bracket. Mounts to standard junction box (not included).
Power supply connections must be made inside junction box.

Finish

White.

Diffuser

White acrylic.

Electrical

Direct wired with a constant current low voltage electronic LED driver rated at 120 VAC. The driver is dimmable down to 10% of full scale with a 2-wire (TRIAC) or electronic low voltage (ELV) dimmer switch.

Lamping

Fixture includes a LED modules capable of producing:
12W = 900 source lumens. 745 delivered lumens.
2700K (CCT). Rated 24/7, working temperature: -20°C – 45°C for 50,000 Hrs. 90 CRI



Certification

Wet location rated for indoor use. Outdoor wet location rated for covered ceiling mount applications ONLY (not recommended for any other outdoor use).
Suitable for use in clothes closets when installed in accordance with the NEC 410.16 spacing requirements.


Options - Sold Separately

Retrofit Kit for 4" and 6" ceiling cans.

Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 years from date-of-purchase.

Specifications and dimensions
subject to change without notice.

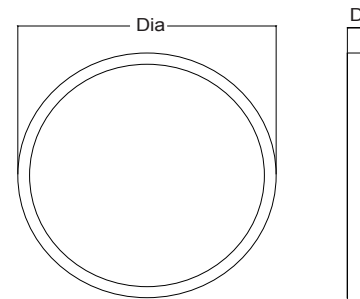

Ordering Information:

White	LED	Source Lumens	Delivered Lumens	CCT	DIA.	D
EGRF0609L27DIWH	12W	900	745	2700K	5-3/8"	3/4"