



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

## Everly LED Outdoor Ceiling EYVW Series



### Features

This outdoor LED light is ideal for security and general lighting. Provides lighting in residential, commercial, and hospitality applications. Fixture mounts to standard junction box (not included).

### Construction

Die-cast aluminum construction. Standard mounting holes and hardware are included. Power supply connections must be made inside a junction box (not included).

### Finish

Black or powder coated or Satin Nickel finish.

### Diffuser

Frosted glass diffuser.

### Electrical

Input 120-277 VAC 60 / HZ.  
Dimmable with 0-10V dimmers.  
Minimum starting temp -4°F / -20°C.

### Lamping

Fixture includes a LED modules capable of producing:  
12W = 1000 delivered lumens  
Selectable 3000K, 3500K, 4000K (CCT).  
Rated for 50,000 Hrs., 90 CRI.


### Certification

All fixtures are cETLus listed for wet locations.  
Title 24/JA8 Compliant

### Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 years from date of purchase.

**Specifications and dimensions  
subject to change without notice.**

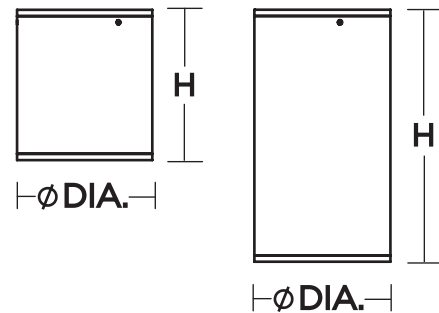

## Ordering Information:

Black	Satin Nickel	LED	Delivered Lumens	Adjustable CCT	DIA.	H
EYVW0405LAJD2BK	EYVW0405LAJD2SN	12W	1000	3000K/3500K/4000K	4-1/4"	4-3/4"
EYVW0408LAJD2BK	EYVW0408LAJD2SN	12W	1000	3000K/3500K/4000K	4-1/4"	8"