



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

Gilbert LED Outdoor Wall GILW Series

Features

Ideal use for general lighting in outdoor residential, commercial, and hospitality applications. Fixture can be mounted to a standard junction box (not included).

Construction

Cast metal housing painted in weather resistant powder coating.
Power supply connections must be made inside a junction box (not included).

Finish

Black, Textured Grey or Oil-Rubbed Bronze finish.

Diffuser

Frosted polycarbonate diffuser.

Electrical

Input 120 VAC / 60Hz.
Minimum starting temp -4° F/-20° C
Integrated photocell for dusk to dawn operation.

LED

Integrated LED modules capable of producing:
35W = 2700 delivered lumens
80W = 7300 delivered lumens
Adjustable Choice 3000K, 4000K, 5000K (CCT).
Rated for 50,000 Hrs. 80 CRI.


Certification

All fixtures are cETLus listed for outdoor wet locations.
Title 24/JA8 Compliant
IP65 Rated

Warranty

5 Year Limited Warranty:
Restrictions apply based on location.

Specifications and dimensions
subject to change without notice.

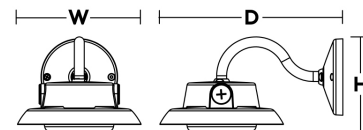

Ordering Information:

Black	Textured Grey	Oil-Rubbed Bronze	LED	Delivered Lumens	Adjustable CCT	H	W	D
GILW0707LAJENBK	GILW0707LAJENTG	GILW0707LAJENBZ	35W	2700	3000K/4000K/5000K	7-1/2"	7-1/2"	12-1/4"
GILW1210LAJENBK	GILW1210LAJENTG	GILW1210LAJENBZ	80W	7300	3000K/4000K/5000K	10-1/4"	11-1/2"	17-1/4"