



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

Octavia LED Flush Mount OTVF Series

Features

Contemporary shallow flush mount fixture can be used in various applications including corridors, baths, laundry rooms and kitchens. Available in three sizes. Fixture mounts to a standard junction box (not included).

Construction

Housing is die formed aluminum band with bowed white diffuser. Back pan is made from 22-gauge stamped steel and painted in lighting grade white. Power supply connections must be made in a junction box (not included).

Finish

Brushed aluminum trim.

Diffuser

.100" thick white acrylic bottom diffuser.

Electrical

Input 120VAC / 60 Hz.
Compatible with Triac or ELV dimmers.

LED

Integrated LED modules capable of producing:
12" - 22W, 1800 source lumens
14" - 33W, 2500 source lumens
19" - 46W, 3200 source lumens
Adjustable Choice 3000K, 3500K, 4000K (CCT).
Rated for 50,000 Hrs., 90 CRI.

Certification

cETLus listed for damp locations
ENERGY STAR® qualified
Title 24/JA8 Compliant


Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 years from date-of-purchase.

**Specifications and dimensions
subject to change without notice.**



3in1 color temperature
3000K/3500K/4000K

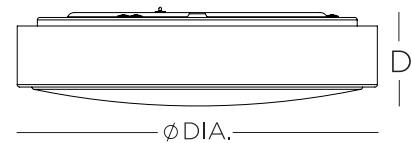

Ordering Information:

Brushed Aluminum	Source		Adjustable CCT	DIA.	D
	LED	Lumens			
OTVF1218LAJD1BA	22W	1800	3000K/3500K/4000K	12"	3"
OTVF1425LAJD1BA	33W	2500	3000K/3500K/4000K	14"	3"
OTVF1932LAJD1BA	46W	3200	3000K/3500K/4000K	19"	3"