



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

Sinclair LED Flush Mount SNF Series

Features

Contemporary flush mount features a simple and clean design with metal accents. Frosted white acrylic diffuser provides indirect lighting.

Construction

Back plate is die-formed of 22-gauge steel. Standard mounting holes and hardware are included. Power supply connections must be made inside a junction box (not included).

Finish

All metal parts are plated satin nickel.

Diffuser

.100" thick frosted white fabricated acrylic diffuser.

Electrical

Input 120-277 VAC 60 HZ.
Compatible with residential (TRIAC/ELV) and commercial (0-10V) dimmers.
TRIAC and ELV dimming only at 120VAC.

LED

Fixture includes a LED modules capable of producing:
14" - 15W, 1400 source lumens
17" - 24W, 2400 source lumens
Adjustable choice 2700K, 3000K, or 3500K (CCT).
Rated for 50,000 Hrs. 90 CRI.

Certification

cETLus listed for damp locations.
Title 24 Compliant with 14" fixture.


Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 years from date-of-purchase.

**Specifications and dimensions
subject to change without notice.**



3in1 color temperature
2700K/3000K/3500K

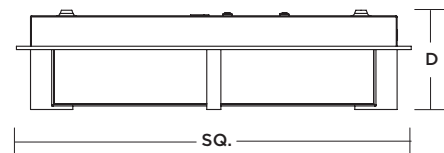

Ordering Information:

Satin Nickel	LED	Source Lumens	Adjustable CCT	SQ.	D
SNF141400LAJUDSN	15W	1400	2700K/3000K/3500K	14"	4-1/2"
SNF172400LAJUDSN	30W	2400	2700K/3000K/3500K	17"	4-1/2"