



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

\*  
**Bailey LED Linear  
 BAYL Series**

**Features**

Decorative linear fixture with a metal finish and a white acrylic diffuser. Ideal use in hallways, entrances or anywhere general lighting is needed. Provides lighting in residential, commercial and hospitality applications. Fixture mounts to standard junction box (not included).



**Bi-Level Motion Sensor (Optional '-MS')**

- Built-in daylight sensor
- Detection area, time delay and daylight threshold can be precisely set via DIP switch
- Wide detection area, range up to 50 ft. (16 m) max

**Emergency Back-Up (Optional '-BB') - 46" ONLY**

- 90 minute run-time
- 7.4V 2500 mAh Lithium Ion Battery
- 8 watts

**Construction**

Die-formed steel construction. Standard mounting holes and hardware are included. Power supply connections must be made inside a junction box (not included).

**Finish**

Black or Satin Nickel.

**Diffuser**

White acrylic.

**Electrical**

Input 120-277 VAC 60 HZ.  
 Compatible with residential (TRIAC/ELV) and commercial (0-10V) dimmers. TRIAC and ELV dimming only at 120 VAC.

**LED**

Integrated LED modules capable of producing:  
 25W = 1875 delivered lumens  
 45W = 3975 delivered lumens  
 Selectable 2700K, 3000K, 3500K, 4000K, 5000K (CCT).  
 Rated for 50,000 Hrs., 90 CRI.


**Certification**

All fixtures are cETLus listed for indoor damp locations.  
 \*Title 24/JA8 Compliant

**Warranty**

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 years from date of purchase.

**Specifications and dimensions**  
 subject to change without notice.

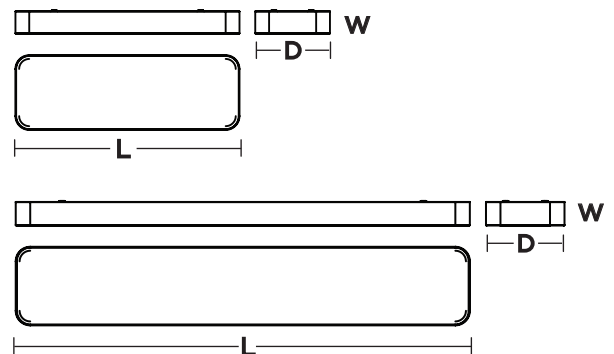

**Ordering Information:**

Black	Satin Nickel	LED Lumens	Adjustable CCT	L	W	D
BAYL2408LAJUDBK*	BAYL2408LAJUDSN*	25W 1875	2700K/3000K/3500K/4000K/5000K	23-3/4"	8"	2-1/2"
BAYL2408LAJUDBK-MS	BAYL2408LAJUDSN-MS	25W 1875	2700K/3000K/3500K/4000K/5000K	23-3/4"	8"	2-1/2"
BAYL4608LAJUDBK*	BAYL4608LAJUDSN*	45W 3975	2700K/3000K/3500K/4000K/5000K	45-1/2"	8"	2-1/2"
BAYL4608LAJUDBK-MS	BAYL4608LAJUDSN-MS	45W 3975	2700K/3000K/3500K/4000K/5000K	45-1/2"	8"	2-1/2"
BAYL4608LAJUDBK-BB	BAYL4608LAJUDSN-BB	45W 3975	2700K/3000K/3500K/4000K/5000K	45-1/2"	8"	2-1/2"
BAYL4608LAJUDBK-MSBB	BAYL4608LAJUDSN-MSBB	45W 3975	2700K/3000K/3500K/4000K/5000K	45-1/2"	8"	2-1/2"