



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

LED Wall Pack WAS Series

Features

All purpose LED wall sconce is an energy saving long-lasting alternative to incandescent. Excellent use in cold climates. LEDs turn on instantly at full brightness. Meets ADA requirements. Ideal use for security and general lighting fixture must be mounted to a standard junction box (not included) on a wall.



Construction

Aluminum construction. Power supply connections must be made inside a junction box (not included).

Finish

All exposed metal surfaces are coated in black powder finish.

Diffuser

White polycarbonate.

Electrical

Input 120 VAC/60 Hz.
Not compatible with dimmers.
Minimum starting temp -4° F/-20° C



LED

Integrated LED modules capable of producing:
9W = 900 source lumens, 650 delivered lumens
3000K (CCT). Rated for 50,000 Hrs. 80 CRI.


Certification

cETLus certified for outdoor wet locations.
ADA
Title 24/JA8 Compliant

Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 years from date-of-purchase.

**Specifications and dimensions
subject to change without notice.**

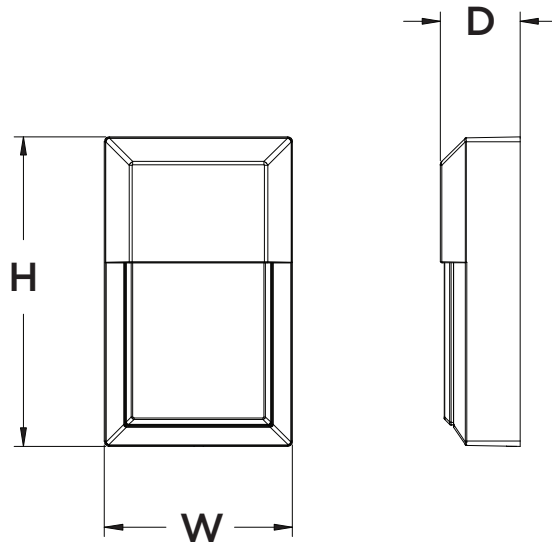

Black	LED	Source Lumens	Delivered Lumens	CCT	H	W	D
WAS08650L30BK	9W	900	650	3000K	8-3/8"	5-1/8"	2-1/8"