



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

Montclair LED Pendant MCP Series

Features

This modern single drum design provides a dramatic look and features Lumafuse™ laminated fabric/acrylic shade. White bottom acrylic diffuser disperses the light. Suspended with a 3 ft. adjustable rigid stem expandable up to 9 ft. Product can be used over reception areas, desks, restaurants, and in public spaces. Canopy mounts to a standard junction box (not included).

Construction

Metal housing and canopy. The canopy fits over a standard junction box. Power supply connections must be made inside a junction box (not included).

Finish

Satin Nickel.

Diffuser

Utilizing Lumafuse™ laminated black fabric to acrylic in Black or Grey. Matte white acrylic bottom diffuser.

Electrical

Input 120-277 VAC 60 HZ.
Compatible with residential (TRIAC/ELV) and commercial (0-10V) dimmers. TRIAC and ELV dimming only at 120 VAC.

LED

Integrated LED modules capable of producing:
12" - 18W = 1400 source lumens
15" - 30W = 2400 source lumens
19" - 42W = 3200 source lumens
Adjustable Choice 3000K, 3500K, 4000K (CCT).
Rated for 50,000 Hrs., 90 CRI.

Certification

All fixtures are cETLus listed for indoor damp locations.


Options

Additional stems sold separately.

Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 year from date of purchase.

Specifications and dimensions
subject to change without notice.

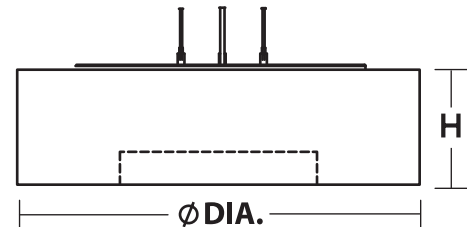

Ordering Information:

Black	Grey	LED	Source Lumens	Adjustable CCT	DIA.	H
MCP1214LAJUDSN-BK	MCP1214LAJUDSN-GY	18W	1400	3000K/3500K/4000K	12-1/4"	3-3/4"
MCP1524LAJUDSN-BK	MCP1524LAJUDSN-GY	30W	2400	3000K/3500K/4000K	15"	4-3/4"
MCP1932LAJUDSN-BK	MCP1932LAJUDSN-GY	42W	3200	3000K/3500K/4000K	19-1/4"	5-1/2"