



LOCATION		DATE
PREPARED BY		QUANTITY
COMMENTS		FIXTURE TYPE
CATALOG NUMBER		

## Sanibel LED Pendant SAP Series



### Features

This modern double layer drum design provides a dramatic look and features Lumafuse™ laminated fabric/acrylic shade in 2 colors. White bottom acrylic diffuser disperses the light. Suspended with a 3 ft. adjustable rigid stem expandable up to 9 ft.

### Construction

Metal housing and canopy. The canopy fits over a standard junction box. Power supply connections must be made inside a junction box (not included).

### Finish

Satin Nickel.

### Diffuser

Utilizing Lumafuse™ laminated fabric to acrylic in Jute or Linen White. Matte white acrylic bottom diffuser.

### Electrical

Input 120-277 VAC 60 HZ.  
Compatible with residential (TRIAC/ELV) and commercial (0-10V) dimmers. TRIAC and ELV dimming only at 120 VAC.

### LED

Integrated LED modules capable of producing:  
16" - 18W = 1400 source lumens  
18" - 30W = 2400 source lumens  
23" - 42W = 3200 source lumens  
Adjustable Choice 3000K, 3500K, 4000K (CCT).  
Rated for 50,000 Hrs., 90 CRI.

### Certification

All fixtures are cETLus listed for indoor damp locations.  
\*Title 24/JA8 Compliant


### Options

Additional stems sold separately.

### Warranty

Limited warranty: This fixture is free from defects in materials and workmanship for a period of 5 year from date of purchase.

Specifications and dimensions subject to change without notice.

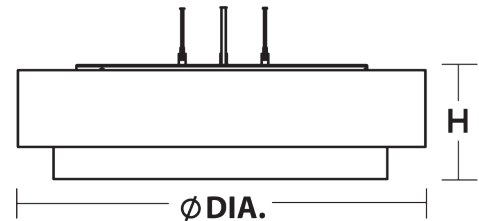

## Ordering Information:

		LED	Source Lumens	Adjustable CCT	DIA.	H
<b>Jute</b>	<b>Linen White</b>					
SAP1614LAJUDSN-JT	SAP1614LAJUDSN-LW	18W	1400	3000K/3500K/4000K	16"	5-5/8"
SAP1824LAJUDSN-JT	*SAP1824LAJUDSN-LW	30W	2400	3000K/3500K/4000K	18"	5-5/8"
SAP2332LAJUDSN-JT	*SAP2332LAJUDSN-LW	42W	3200	3000K/3500K/4000K	23-1/4"	5-5/8"