



Style #2175

- > Flame Resistant
- > Full body harness
- > ANSI User Capacity:
130lb to 310lb max
- > OSHA User Capacity:
130lb to 425lb max
- > Five adjustments on chest,
shoulders, and legs
- > Kevlar® and Nomex® webbing
- > Kevlar® and Nomex® sewn-in thread
- > Dielectric dorsal D-ring
- > Dielectric buckle
- > Meets ANSI Z359.11
- > Sizes:
SM-MD
LG-XL
2XL-3XL

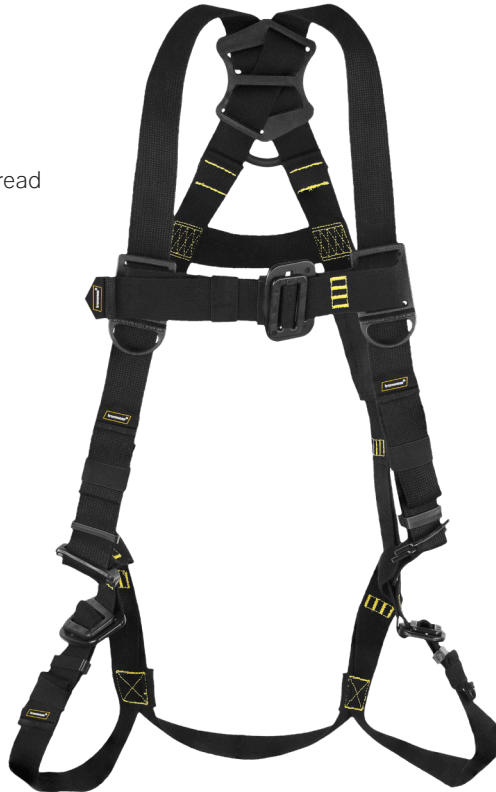

(Front)

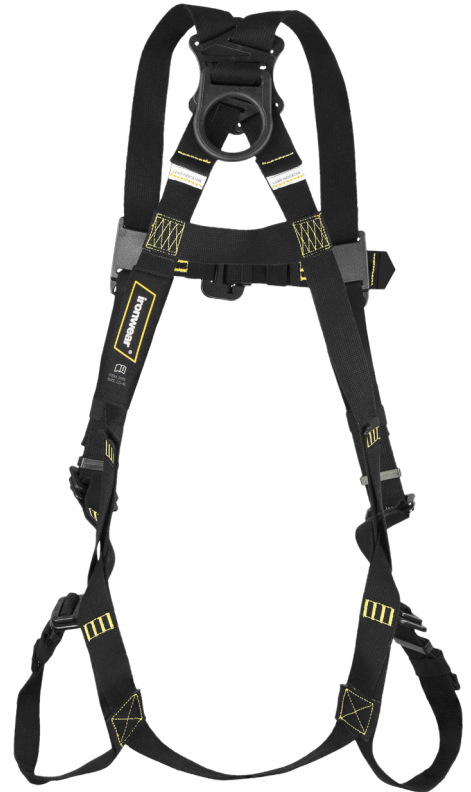

(Back)

Packaging

- > Color: Black with yellow accent stitching
- > Unit: Each
- > Case Pack: 8
- > Case Weight (lb/kg): 26.6 / 12.1
29.2 / 13.2
32.2 / 14.6
- > Case Dimensions (in): 22 x 13 x 11
- > Case Dimensions (cm): 55.9 x 33 x 27.9