

Stock Code: **20032LEDMG-BRZ/FST**

Collection: Bayside

**PRODUCT INFORMATION**

Base: 20032 Parent: 20032LEDMG  
Mounting Type: Wall UPC: 641594223255  
Finish: Bronze  
Diffuser: Frosted

**PRODUCT MEASUREMENTS**

<b>FIXTURE</b>	<b>BACKPLATE / CANOPY</b>
Length:	Length 0.5"
Width: 4.5"	Width: 4.5"
Diameter	Diameter:
Height: 8"	Height: 4.5"
Extension: 5.5"	
Overall Height:	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Aluminum  
 Diffuser Material: Glass  
 Lamping Type: SSL (Dedicated LED) Jbox: Standard  
 Lamping Base: SSL Lamp Wattage: 15 W  
 Lamp Quantity: 1 Total Wattage: 15 W  
 Voltage: 120v Lamps Included: Yes

**QUALIFICATIONS**

Location Rating Wet  
 Certification: ETL (US/Canada) Listed  
 ADA Compliant: No Energy Star: No  
 JA8 Compliant: Outdoor Only Emergency Lighting: No  
 Marine Grade Finish: Yes  
 Warranty: 5 Year

**PHOTOMETRICS**

Dimmable: No Nominal Lumens 1000 Lm  
 CRI: 90 Delivered Lumens: 590 Lm  
 CCT: 3000K  
 Recommended Dimmers:


**ADDITIONAL NOTES**

Custom Finish 100 Piece Minimum Order Quantity; Optional Color Temperature 100 Piece Minimum Order Quantity


Project Name: \_\_\_\_\_  
 Location: \_\_\_\_\_  
 Type: \_\_\_\_\_  
 Quantity: \_\_\_\_\_  
 Notes: \_\_\_\_\_



**LINE DRAWING**

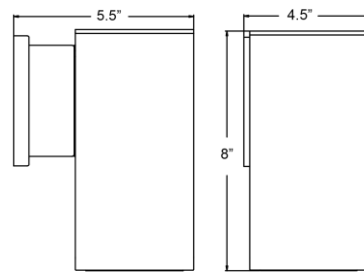

**IES FILE**

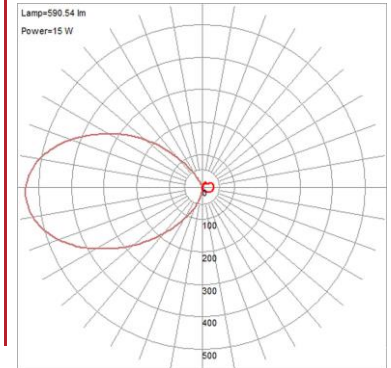

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

