

Stock Code: **20033LEDMG-SAT/FST**

Collection: Bayside

PRODUCT INFORMATION

Base: 20033 Parent: 20033LEDMG
Mounting Type: Wall UPC: 641594223170
Finish: Satin
Diffuser: Frosted

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length 0.5"
Width: 4.5"	Width: 4.5"
Diameter	Diameter:
Height: 12"	Height: 4.5"
Extension: 5.5"	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Aluminum	
Diffuser Material: Glass	
Lamping Type: SSL (Dedicated LED)	Jbox: Standard
Lamping Base: SSL	Lamp Wattage: 15 W
Lamp Quantity: 2	Total Wattage: 30 W
Voltage: 120v	Lamps Included: Yes

QUALIFICATIONS

Location Rating Wet	
Certification: ETL (US/Canada) Listed	
ADA Compliant: No	Energy Star: No
JA8 Compliant: Outdoor Only	Emergency Lighting: No
Marine Grade Finish: Yes	
Warranty: 5 Year	

PHOTOMETRICS

Dimmable: No	Nominal Lumens 2100 Lm
CRI: 90	Delivered Lumens: 1352 Lm
CCT: 3000K	
Recommended Dimmers:	

ADDITIONAL NOTES

Bi-Directional Light Source; Optional Color Tempature 100 Piece Minimum Order Quantity; Custom Finish 100 Piece Minimum Order Quantity

Project Name: _____

Location: _____


Type: _____

Quantity: _____


Notes: _____



LINE DRAWING

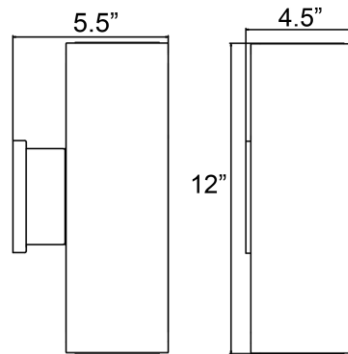

IES FILE

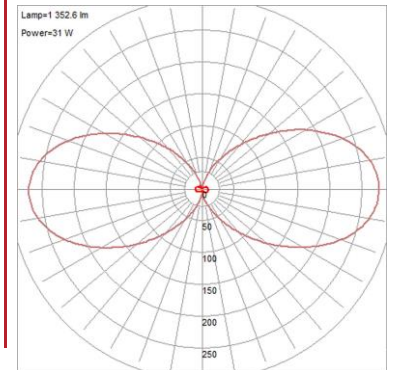

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

