

Stock Code: **20076LEDD-SILV/ACR**

Collection: **Ulko**

PRODUCT INFORMATION

Base: 20076 Parent: 20076LEDD
Mounting Type: Ceiling UPC: 641594224580
Finish: Silver
Diffuser: Acrylic Lens

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length: 9"	Length
Width: 9"	Width:
Diameter	Diameter:
Height: 1"	Height:
Extension:	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Acrylic
 Diffuser Material: Acrylic
 Lamping Type: SSL (Dedicated LED) Jbox: Standard
 Lamping Base: SSL Lamp Wattage: 20 W
 Lamp Quantity: 1 Total Wattage: 20 W
 Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Wet
 Certification: ETL (US/Canada) Listed
 ADA Compliant: No Energy Star: No
 JA8 Compliant: Outdoor Only Emergency Lighting: No
 Marine Grade: No Warranty: 5 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 1800 Lm
 CRI: 90 Delivered Lumens: 1349 Lm
 CCT: 3000K
 Recommended Dimmers:
 (TRIAC)LEVITON Trimatron 6684; (TRIAC)LEVITON Surslide 6631;
 (TRIAC)LEVITON Decora Sureslide 6674; (ELV)LUTRON Skylark SELV-300P;
 (TRIAC)LUTRON Diva DV-600P; (TRIAC)LUTRON Diva DVCL-153P;
 (MLV)LUTRON Diva DVLV-600P


Additional Notes:

Custom Finish 200 Piece Minimum Order Quantity; Optional Color Temperature 200 Piece Minimum Order Quantity

Project Name: _____
 Location: _____
 Type: _____
 Quantity: _____
 Notes: _____



LINE DRAWING

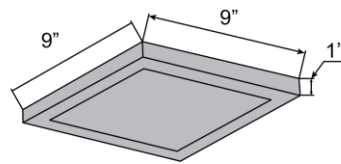

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

