

Stock Code: **20090LEDMG-BRZ/ACR**

Collection: **GEO**

**PRODUCT INFORMATION**

Base: 20090 Parent: 20090LEDMG  
Mounting Type: Wall UPC: 641594244441  
Finish: Bronze  
Diffuser: Acrylic Lens

**PRODUCT MEASUREMENTS**

<b>FIXTURE</b>	<b>BACKPLATE / CANOPY</b>
Length:	Length
Width: 6.5"	Width:
Diameter	Diameter:
Height: 12"	Height:
Extension: 4"	
Overall Height:	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Steel  
Diffuser Material: Acrylic  
Lamping Type: SSL (Dedicated LED) Jbox: Standard  
Lamping Base: SSL Lamp Wattage: 15 W  
Lamp Quantity: 1 Total Wattage: 15 W  
Voltage: 120-277v Lamps Included: Yes

**QUALIFICATIONS**

Location Rating Wet  
Certification: ETL (US/Canada) Listed  
ADA Compliant: Yes Energy Star: No  
JA8 Compliant: Outdoor Only Emergency Lighting: No  
Marine Grade Finish: Yes  
Warranty: 5 Year

**PHOTOMETRICS**

Dimmable: Yes Nominal Lumens 1400 Lm  
CRI: 90 Delivered Lumens: 1040 Lm  
CCT: 3000K  
Recommended Dimmers:  
(TRIAC)LUTRON Diva DVCL-153P; (ELV)LUTRON Maestro CL  
MACL-153M


**ADDITIONAL NOTES**

Optional Color Tempature 100 Piece Minimum Order Quantity;  
Custom Finish 100 Piece Minimum Order Quantity


Project Name: \_\_\_\_\_  
Location: \_\_\_\_\_  
Type: \_\_\_\_\_  
Quantity: \_\_\_\_\_  
Notes: \_\_\_\_\_



**LINE DRAWING**

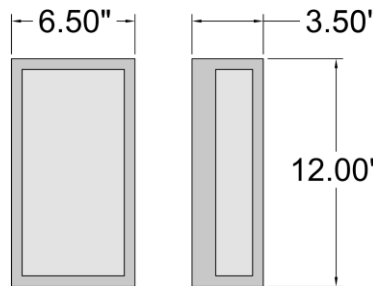

**IES FILE**

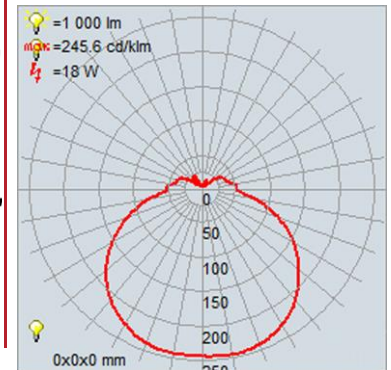

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

