

Stock Code: **20107LEDMG-BRZ/ACR**

Collection: Cove

**PRODUCT INFORMATION**

Base: 20107 Parent: 20107LEDMG  
Mounting Type: Wall UPC: 641594223323  
Finish: Bronze  
Diffuser: Acrylic Lens

**PRODUCT MEASUREMENTS**

<b>FIXTURE</b>	<b>BACKPLATE / CANOPY</b>
Length:	Length
Width: 6.25"	Width: 3.25"
Diameter	Diameter:
Height: 24"	Height: 24"
Extension: 4"	
Overall Height:	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Metal	
Diffuser Material: Acrylic	
Lamping Type: SSL (Dedicated LED)	Jbox: Standard
Lamping Base: SSL	Lamp Wattage: 23 W
Lamp Quantity: 1	Total Wattage: 23 W
Voltage: 120-277v	Lamps Included: Yes

**QUALIFICATIONS**

Location Rating: Wet	
Certification: ETL (US/Canada) Listed	
ADA Compliant: Yes	Energy Star: No
JA8 Compliant: Outdoor Only	Emergency Lighting: No
Marine Grade Finish: Yes	
Warranty: 5 Year	

**PHOTOMETRICS**

Dimmable: No	Nominal Lumens: 1400 Lm
CRI: 90	Delivered Lumens: 1158 Lm
CCT: 3000K	
Recommended Dimmers:	


**ADDITIONAL NOTES**

Custom Finish 5 Piece Minimum Order Quantity; Optional Color Temperature 100 Piece Minimum Order Quantity


Project Name: \_\_\_\_\_  
 Location: \_\_\_\_\_  
 Type: \_\_\_\_\_  
 Quantity: \_\_\_\_\_  
 Notes: \_\_\_\_\_



**LINE DRAWING**

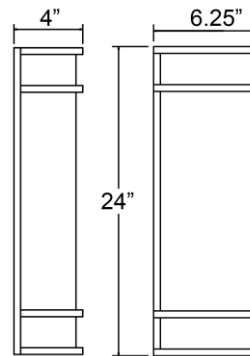

**IES FILE**

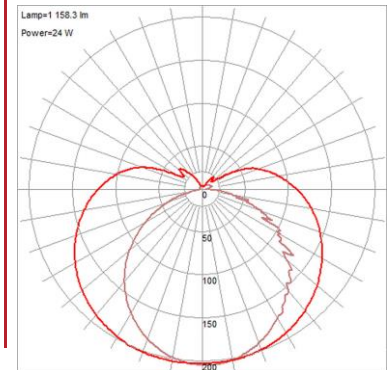

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

