

Stock Code: **20341LEDDMGLP-BRZ/FST**

Collection: Zone Dual Mount

PRODUCT INFORMATION

Base: 20341 Parent: 20341LEDDMG
Mounting Type: Ceiling or Wall UPC: 641594244588
Finish: Bronze
Diffuser: Frosted

PRODUCT MEASUREMENTS

| FIXTURE | BACKPLATE / CANOPY |
|-----------------|--------------------|
| Length: | Length |
| Width: 4.5" | Width: |
| Diameter | Diameter: |
| Height: 7.5" | Height: |
| Extension: 6.5" | |
| Overall Height: | |

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Steel
Diffuser Material: Glass
Lamping Type: GU-10 (Replaceable LE Jbox: Standard
Lamping Base: GU-10 Lamp Wattage: 5.5 W
Lamp Quantity: 1 Total Wattage: 5.5 W
Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Wet
Certification: ETL (US/Canada) Listed
ADA Compliant: No Energy Star: No
JA8 Compliant: Yes Emergency Lighting: No
Marine Grade Finish: Yes
Warranty: 5 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 500 Lm
CRI: 90 Delivered Lumens: N/A
CCT: 3000K
Recommended Dimmers:
(MLV)COOPER Aspire 9530SW; (TRIAC)LEGRAND Titan
CD703-PW; (TRIAC)LUTRON Diva DVCL-153P; (ELV)LUTRON
Skylark SELV-300P; (ELV)LUTRON Diva DVELV-300P

ADDITIONAL NOTES

Custom Finish 100 Piece Minimum Order Quantity

Project Name: _____

Location: _____


Type: _____

Quantity: _____

Notes: _____



LINE DRAWING

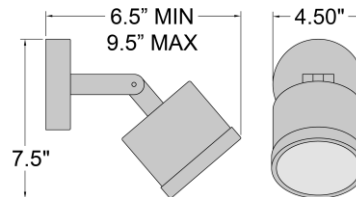

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice. 12/22/2022 20341LEDDMGLP-BRZ_FST.pdf

