

Stock Code: **20775LEDD-BRZ/OPL**

Collection: Solid

### PRODUCT INFORMATION

Base: 20775 Parent: 20775LEDD  
Mounting Type: Ceiling UPC: 641594198218  
Finish: Bronze  
Diffuser: Opal

### PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 9"	Diameter:
Height: 3"	Height:
Extension:	
Overall Height:	

### TECHNICAL SPECIFICATIONS

#### SPECIFICATIONS

Frame Material: Metal  
Diffuser Material: Glass  
Lamping Type: SSL (Dedicated LED) Jbox: Standard  
Lamping Base: SSL Lamp Wattage: 17 W  
Lamp Quantity: 1 Total Wattage: 17 W  
Voltage: 120v Lamps Included: Yes

#### QUALIFICATIONS

Location Rating Damp  
Certification: UL (US/Canada) Listed  
ADA Compliant: No Energy Star: Yes  
JA8 Compliant: No Emergency Lighting: No  
Marine Grade: No Warranty: 5 Year

#### PHOTOMETRICS

Dimmable: Yes Nominal Lumens 1440 Lm  
CRI: 90 Delivered Lumens: 715 Lm  
CCT: 3000K  
Recommended Dimmers:  
(ELV)LUTRON Diva DVELV-300P; (ELV)LUTRON Skylark SELV-300P; (ELV)LEGRAND Paddle ADPD453LM2; (ELV)LUTRON Diva DVELV-303P; (TRIAC)LUTRON Diva DV-600P

Additional Notes:

Project Name: \_\_\_\_\_

Location: \_\_\_\_\_


Type: \_\_\_\_\_

Quantity: \_\_\_\_\_


Notes:



#### LINE DRAWING

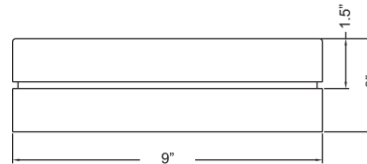

#### IES FILE

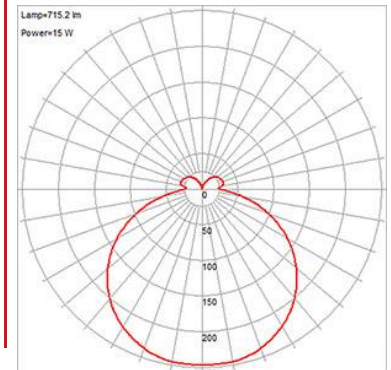

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

Toll Free 800-828-5483 [www.AccessLighting.com](http://www.AccessLighting.com)

14410 Myford Road, Irvine, CA 92606

