

Stock Code: **31033-BS/ACR**

Collection: Sequoia

PRODUCT INFORMATION

Base: 31033 Parent: 31033
Mounting Type: Wall UPC: 641594148930
Finish: Brushed Steel
Diffuser: Acrylic Lens

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length 36.75"
Width: 37"	Width: 5.25"
Diameter	Diameter:
Height: 5.5"	Height: 0.75"
Extension: 3.75"	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Metal
Diffuser Material: Acrylic
Lamping Type: Bi-Pin (Fluorescent) Jbox: Standard
Lamping Base: Bi-Pin Lamp Wattage: 39 W
Lamp Quantity: 2 Total Wattage: 78 W
Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Damp
Certification: UL (US/Canada) Listed
ADA Compliant: Yes Energy Star: No
JA8 Compliant: No Emergency Lighting: No
Marine Grade: No Warranty: 1 Year

PHOTOMETRICS


Dimmable: No Nominal Lumens 6200 Lm
CRI: N/A Delivered Lumens: N/A
CCT: 3000K
Recommended Dimmers:

Additional Notes:
Horizontal and Vertical Mounting

Project Name: _____
Location: _____
Type: _____
Quantity: _____
Notes:



LINE DRAWING

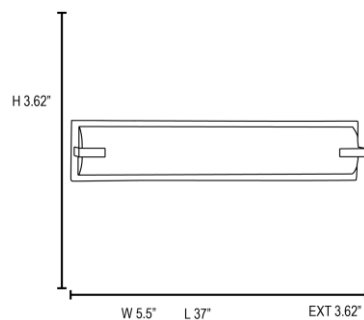

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice. 12/15/2022 31033-BS_ACR.pdf

