

Stock Code: **52043LEDDLPL-BL**

Collection: Viper

**PRODUCT INFORMATION**

Base: 52043 Parent: 52043LEDDLPL  
Mounting Type: Ceiling UPC: 641594234992  
Finish: Black  
Diffuser: N/A

**PRODUCT MEASUREMENTS**

<b>FIXTURE</b>	<b>BACKPLATE / CANOPY</b>
Length: 62"	Length 6"
Width: 6"	Width: 11"
Diameter	Diameter:
Height: 9"	Height:
Extension:	
Overall Height:	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Metal  
 Diffuser Material: N/A  
 Lamping Type: GU-10 (Replaceable LE Jbox: Standard  
 Lamping Base: GU-10 Lamp Wattage: 5.5 W  
 Lamp Quantity: 6 Total Wattage: 33 W  
 Voltage: 120v Lamps Included: Yes

**QUALIFICATIONS**

Location Rating Dry  
 Certification: UL (US/Canada) Listed  
 ADA Compliant: No Energy Star: No  
 JA8 Compliant: Yes Emergency Lighting: No  
 Marine Grade: No Warranty: 1 Year

**PHOTOMETRICS**

Dimmable: Yes Nominal Lumens 2400 Lm  
 CRI: 90 Delivered Lumens: N/A  
 CCT: 3000K  
 Recommended Dimmers:  
 (TRIAC)LEGRAND Titan CD703-PW; (ELV)LUTRON Skylark  
 SELV-300P; (MLV)COOPER Aspire 9530SW


**Additional Notes:**

Custom Finish 100 Piece Minimum Order Quantity

Project Name: \_\_\_\_\_  
 Location: \_\_\_\_\_  
 Type: \_\_\_\_\_  
 Quantity: \_\_\_\_\_  
 Notes: \_\_\_\_\_



**LINE DRAWING**

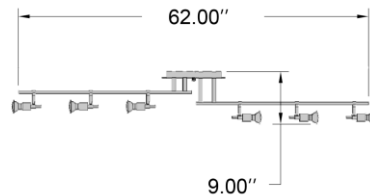

**IES FILE**

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

