

Stock Code: **52057-WH/WGN**

Collection: Blend

**PRODUCT INFORMATION**

Base: 52057 Parent: 52057  
Mounting Type: Ceiling UPC: 641594238730  
Finish: White  
Diffuser: N/A

**PRODUCT MEASUREMENTS**

<b>FIXTURE</b>	<b>BACKPLATE / CANOPY</b>
Length:	Length
Width:	Width:
Diameter 12"	Diameter: 5"
Height: 9"	Height: 1"
Extension:	
Overall Height: 14-130"	

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

Frame Material: Metal	
Diffuser Material: N/A	
Lamping Type: N/A	Jbox: Standard
Lamping Base: E-26	Lamp Wattage: 60 W
Lamp Quantity: 1	Total Wattage: 60 W
Voltage: 120v	Lamps Included: No

**QUALIFICATIONS**

Location Rating Dry	
Certification: UL (US/Canada) Listed	
ADA Compliant: No	Energy Star: No
JA8 Compliant: No	Emergency Lighting: No
Marine Grade: No	Warranty: 1 Year

**PHOTOMETRICS**

Dimmable: Yes	Nominal Lumens N/A
CRI: N/A	Delivered Lumens: N/A
CCT: N/A	
Recommended Dimmers:	

**Additional Notes:**

10 feet of white cord included; Custom Finish 100 Piece Minimum Order Quantity

Project Name: \_\_\_\_\_

Location: \_\_\_\_\_


Type: \_\_\_\_\_

Quantity: \_\_\_\_\_

Notes: \_\_\_\_\_



**LINE DRAWING**

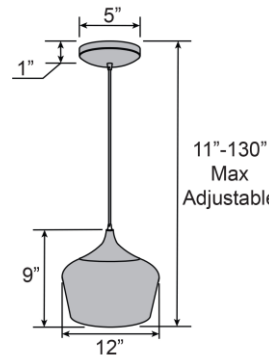

**IES FILE**

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

