

Stock Code: **62052-CH/CKF**

Collection: Oxygen

**PRODUCT INFORMATION**

Base: 62052 Parent: 62052  
Mounting Type: Wall UPC: 641594821444  
Finish: Chrome  
Diffuser: Checkered Frosted

**PRODUCT MEASUREMENTS**

|                  |                           |
|------------------|---------------------------|
| <b>FIXTURE</b>   | <b>BACKPLATE / CANOPY</b> |
| Length:          | Length                    |
| Width: 25.25"    | Width:                    |
| Diameter         | Diameter:                 |
| Height: 6.75"    | Height:                   |
| Extension: 4.25" |                           |
| Overall Height:  |                           |

**TECHNICAL SPECIFICATIONS**

**SPECIFICATIONS**

|                             |                      |
|-----------------------------|----------------------|
| Frame Material: Metal       |                      |
| Diffuser Material: Glass    |                      |
| Lamping Type: R7s (Halogen) | Jbox: Standard       |
| Lamping Base: R7s           | Lamp Wattage: 100 W  |
| Lamp Quantity: 2            | Total Wattage: 200 W |
| Voltage: 120v               | Lamps Included: Yes  |

**QUALIFICATIONS**

|                                      |                        |
|--------------------------------------|------------------------|
| Location Rating Damp                 |                        |
| Certification: UL (US/Canada) Listed |                        |
| ADA Compliant: No                    | Energy Star: No        |
| JA8 Compliant: No                    | Emergency Lighting: No |
| Marine Grade: No                     | Warranty: 1 Year       |

**PHOTOMETRICS**

|  |                        |
|--|------------------------|
| Dimmable: Yes                                      | Nominal Lumens 5200 Lm |
| CRI: N/A   | Delivered Lumens: N/A  |
| CCT: 2900K   |                        |
| Recommended Dimmers:<br>(TRIAC)Any Standard Dimmer |                        |

Additional Notes:

Custom Finish 5 Piece Minimum Order Quantity

Project Name: \_\_\_\_\_

Location: \_\_\_\_\_


Type: \_\_\_\_\_

Quantity: \_\_\_\_\_

Notes:



**LINE DRAWING**

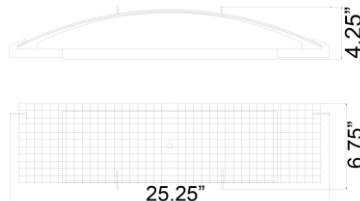

**IES FILE**

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

**Toll Free 800-828-5483 www.AccessLighting.com**

14410 Myford Road, Irvine, CA 92606

