

Stock Code: **62105-BS/OPL**

Collection: Argon

PRODUCT INFORMATION

Base: 62105 Parent: 62105
Mounting Type: Wall UPC: 641594019155
Finish: Brushed Steel
Diffuser: Opal

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length 19.75"
Width: 22.5"	Width: 4.25"
Diameter	Diameter:
Height: 5.25"	Height: 1"
Extension: 3.5"	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Metal
Diffuser Material: Glass
Lamping Type: R7s (Halogen) Jbox: Standard
Lamping Base: R7s Lamp Wattage: 100 W
Lamp Quantity: 2 Total Wattage: 200 W
Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Damp
Certification: ETL (US/Canada) Listed
ADA Compliant: Yes Energy Star: No
JA8 Compliant: No Emergency Lighting: No
Marine Grade: No Warranty: 1 Year

PHOTOMETRICS


Dimmable: Yes Nominal Lumens 3300 Lm
CRI: N/A Delivered Lumens: N/A
CCT: 2900K
Recommended Dimmers:
(TRIAC)Any Standard Dimmer

Additional Notes:

Project Name: _____
Location: _____
Type: _____
Quantity: _____
Notes: _____



LINE DRAWING

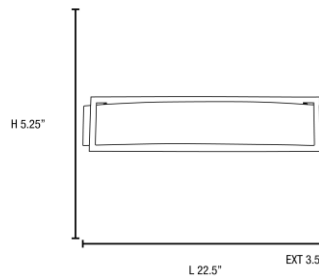

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice. 12/15/2022 62105-BS_OPL.pdf

