

Stock Code: **63120LEDDL-CH/CLR**

Collection: **Burst**

PRODUCT INFORMATION

Base: 63120 Parent: 63120LEDDL
Mounting Type: Ceiling UPC: 641594230178
Finish: Chrome
Diffuser: Clear

PRODUCT MEASUREMENTS

FIXTURE	BACKPLATE / CANOPY
Length:	Length
Width:	Width:
Diameter 21.25"	Diameter: 4.75"
Height: 11"	Height:
Extension:	
Overall Height:	

TECHNICAL SPECIFICATIONS

SPECIFICATIONS

Frame Material: Metal
Diffuser Material: Glass
Lamping Type: G9 (Replaceable LED) Jbox: Standard
Lamping Base: G9 Lamp Wattage: 4.5 W
Lamp Quantity: 6 Total Wattage: 27 W
Voltage: 120v Lamps Included: Yes

QUALIFICATIONS

Location Rating Dry
Certification: UL (US/Canada) Listed
ADA Compliant No Energy Star: No
JA8 Compliant: No Emergency Lighting: No
Marine Grade: No Warranty: 1 Year

PHOTOMETRICS

Dimmable: Yes Nominal Lumens 2700 Lm
CRI: 80 Delivered Lumens: N/A
CCT: 3000K
Recommended Dimmers:
(ELV)LUTRON Diva DVELV-303P; (ELV)LUTRON Skylark SELV-300P; (ELV)LUTRON Diva DVELV-300P; (TRIAC)LUTRON Diva DVCL-153P


Additional Notes:

Project Name: _____
Location: _____
Type: _____
Quantity: _____
Notes: _____



LINE DRAWING

IES FILE

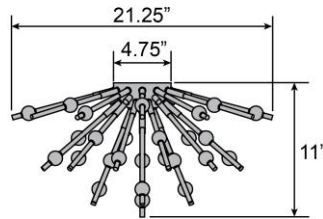

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: _____

Print Name _____ Date: _____

Toll Free 800-828-5483 www.AccessLighting.com

14410 Myford Road, Irvine, CA 92606

