

Stock Code: **89123-CRM**

Collection: Rumanian Silk

### PRODUCT INFORMATION

Base: 89123 Parent: 89123  
Mounting Type: N/A UPC: 641594025996  
Finish: N/A  
Diffuser: Cream

### PRODUCT MEASUREMENTS

| FIXTURE         | BACKPLATE / CANOPY |
|-----------------|--------------------|
| Length:         | Length             |
| Width:          | Width:             |
| Diameter 3.5"   | Diameter:          |
| Height: 12"     | Height:            |
| Extension:      |                    |
| Overall Height: |                    |

### TECHNICAL SPECIFICATIONS

#### SPECIFICATIONS

Frame Material: Glass  
Diffuser Material: Glass  
Lamping Type: N/A Jbox: N/A  
Lamping Base: N/A Lamp Wattage: N/A  
Lamp Quantity: N/A Total Wattage: N/A  
Voltage: N/A Lamps Included: No

#### QUALIFICATIONS

Location Rating N/A  
Certification: N/A  
ADA Compliant No Energy Star: No  
JA8 Compliant: No Emergency Lighting: No  
Marine Grade: No Warranty: 1 Year

#### PHOTOMETRICS

Dimmable: No Nominal Lumens N/A  
CRI: N/A Delivered Lumens: N/A  
CCT: N/A  
Recommended Dimmers:

Additional Notes:

Project Name: \_\_\_\_\_

Location: \_\_\_\_\_


Type: \_\_\_\_\_

Quantity: \_\_\_\_\_

Notes:



LINE DRAWING

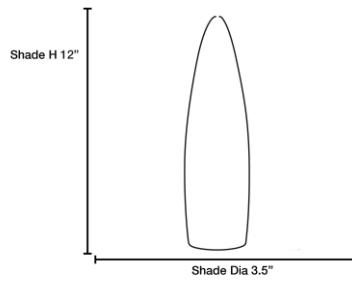

IES FILE

In addition to Access Lighting's purchase and warranty terms and conditions, by signing below or placing an order, you agree that you are authorized to bind the entity placing any order and acknowledge the following: All of sizes and measurements are approximate and all images are for illustrative purposes only. In the event of an inconsistency, the "Product Measurements" section controls. There also may be slight differences in the colors and designs compared to the displayed and printed images.

Signature: \_\_\_\_\_

Print Name \_\_\_\_\_ Date: \_\_\_\_\_

Toll Free 800-828-5483 [www.AccessLighting.com](http://www.AccessLighting.com)

14410 Myford Road, Irvine, CA 92606

The information is subject to change without notice. 9/23/2022 89123-CRM.pdf

