

# 1000VA Battery Backup

## Line-Interactive Mini-Tower UPS

0E-1000V9RD

**UltraTech**  
POWER PRODUCTS

### PRODUCT DESCRIPTION

A mini-tower UPS with line interactive topology, the UltraTech 0E-1000V9RD provides battery backup and surge protection for desktop computers, workstations, network devices and home entertainment systems. The 0E-1000V9RD uses Automatic Voltage Regulation (AVR) to correct minor power fluctuations without switching to battery power, which extends battery life and is essential in areas where power fluctuations occur frequently.

### FEATURES

- 9 Grounded Outlets, 5 with Battery Backup
- Automatic Voltage Regulation (AVR)
- HID Compliant USB Connectivity Port
- EMI and RFI Filtration
- Simulated Sine Wave Output
- LCD Display
- PowerPanel® Personal Software for Remote Monitoring and Management



### SPECIFICATIONS

PART #	0E-1000V9RD
UPC	840049300613
CAPACITY	1000VA / 600W
OUTPUT	120 VAC +/- 5%
CORD LENGTH	6 ft. (1.8m)
OUTLET TYPES	9 x NEMA 5-15R
RUNTIME (HALF/FULL)	9 minutes / 2 minutes
DIMENSIONS	3.9 x 9 x 10.2 in. (99 x 229 x 259mm)
WEIGHT	15 lbs. (6.8kg)
WARRANTY	3-year
CONNECTED EQUIPMENT GUARANTEE	\$350,000

### TYPICAL APPLICATIONS

- Desktop Computers
- Workstations
- Home Theater Equipment
- Personal Electronics
- Home Networking
- Routers & Modems
- VoIP Phone Systems




# 1000VA Battery Backup

Line-Interactive Mini-Tower UPS



Multifunction LCD

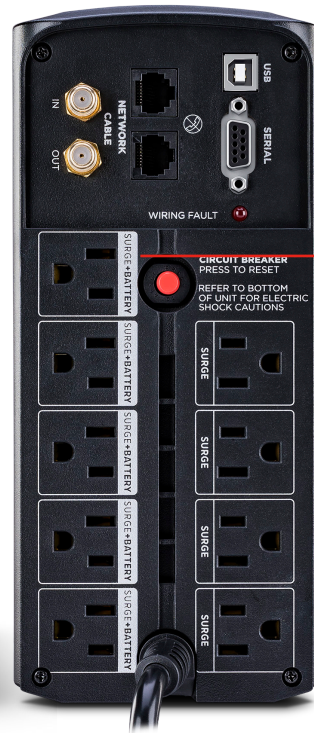

USB & Serial Connectivity Ports  
Broadband Network / Modem / DSL Protection  
COAX / Cable / DSS Surge Protection

5 Battery + Surge Protected Outlets

4 Surge Protected Outlets

## ADDITIONAL SPECIFICATIONS

INPUT	Circuit Breaker	15A
	Cord Length	6 ft. (1.8m)
	Input Frequency Range	57 Hz-63 Hz
	Nominal Input Voltage	120 VAC
OUTPUT	On Battery Frequency	60 Hz +/- 1%
	On Battery Voltage	120 VAC +/- 5%
	On Battery Waveform	Simulated Sine Wave
	UPS Topology	Line Interactive
	Overload Protection	Internal Circuitry Limiting, Circuit Breaker Protected
	Typical Transfer Time	4 ms
	BATTERY	Battery Quantity
Battery Size		12V / 9Ah
Battery Type		Sealed Lead-Acid
Typical Recharge Time		8 hours

# 1000VA Battery Backup

Line-Interactive Mini-Tower UPS



## ADDITIONAL SPECIFICATIONS (CONT.)

<b>SURGE PROTECTION AND FILTERING</b>	Coax Protection RG6	1-in / 1-out
	EMI / RFI Filtration	Yes
	Network Protection RJ45	1-in / 1-Out (10/100/1000)
	Surge Suppression	1080 J
<b>MANAGEMENT AND COMMUNICATIONS</b>	Audible Alarms	Battery Mode / Low Battery Overload / Fault
	HID Compliant USB Port	Yes
	LCD	Multifunction LCD
	LED Indicators	Power On / Wiring Fault
	Management Cable	USB Cable
	Software (Free Download)	PowerPanel® Personal
<b>PHYSICAL SPECIFICATIONS</b>	Form Factor	Mini-Tower
	Material of Construction	Plastic
<b>WEIGHTS AND DIMENSIONS</b>	Width/Height/Depth (in) Width/Height/Depth (cm) Width/Height/Depth (mm)	3.9 x 9 x 10.2 in. 9.91 x 22.86 x 25.91cm 99 x 229 x 259mm
	Weight (lb) Weight (kg)	15 lbs. 6.8kg
<b>ENVIRONMENTAL</b>	Operating Relative Humidity	0 - 90% (non-condensing)
	Operating Temperature	32-104°F (0-40°C)
	Storage Temperature	5-113°F (-15-45°C)
<b>CERTIFICATIONS</b>	Environmental	RoHS Compliant
	Safety	UL1778 cUL 107 5th FCC DOC Class B
<b>WARRANTY</b>	CEG Amount	\$350,000
	Product Warranty	3-Year Limited