

26-Port Gigabit PoE Switch

**24 Port PoE +2 Shared
Port (RJ-45 or SFP) Uplinks**

0E-24PRJ45FG



The 26Port/24 PoE Switch is fully integrated to support security monitoring, provides Gigabit packet forwarding capability, as well as fast Ethernet transfer rates by utilizing the appropriate bandwidth to ensure clear images/smooth transmission and enough bandwidth for high-definition video.

- 24 x 10/100/1000Mbps PoE Ports
- 2 x Shared Gigabit Uplinks (RJ-45 or SFP)
- Internal Power Supply
- 370W PoE Budget
- Switching Capacity: 52 gbps
- Port/PoE Status: LED
- 19" Rack Mountable Housing
- 6KV Surge Protection
- Warranty: Limited Lifetime

PART # : 0E-24PRJ45FG

UPC : 840049305137

Input of Power Supply: 100-240 VAC

Transmission Distance: 100 Meter (328ft)

MAC Address: 8K MAC Address Table

Dimension : 17.3" x 7.8" x 1.7"
440mm x 200mm x 44mm

Weight : 8.2 lb
3.7 kg

Product Certification:



SPEC SHEET



Item		Description	
Power	Power Supply	Built-in power supply	
	Input Vlotage	100~240VAC	
	Output Vlotage	52 VDC	
	PoE Budget	370W for 24 PoE ports	
Ethernet	Speed	1~24 Port: 10/100/1000Mbps 25-26 Port: Shared Gigabit Port (RJ-45 or SFP)	
	Transmission Distance	RJ-45: 328ft (100 meters) SFP Port: Transmission distances vary with type of SFP module used. SFP module not included	
Network Switch	Ethernet Standards	IEEE 802.3/802.3u/802.3ab/802.3af/at	
	Switching Capacity	52Gbps	
	Transfer Rate	14,880pps for 10Mbps	
		148,800pps for 100Mbps	
		1,488,000pps for 1000Mbps	
MAC Address	8K MAC address table		
LINK/ACT Indicator	On	Green	The port is connected
	Blinks	-	The port is receiving or transmitting data
	Off	-	The port is not linked successfully with the device
PoE Indicator	On	Green	Power Device is connected
	Off	-	Power device is not connected or power forwarding fails
	PoE pin assignmnet		V+(RJ-45 Pin 1,2), V-(RJ-45 Pin 3,6)
Environment	Working Temperature		0~40°C (32~104 Deg. F)
	Storage Temperature		-40~70°C (-40~158 Deg. F)
	Humidity non-condensing		0~85%
Mechanical	Dimension L* W * H		17.3" x 7.8" x 1.7"
			440 x 200 x 44mm
	Color		Black


FOR MORE INFORMATION,
CONTACT YOUR ADI SALES PERSON.

wboxtech.com

Board Diagram

Front

4 Uplink Ports can be used 2 out of 4 at a time

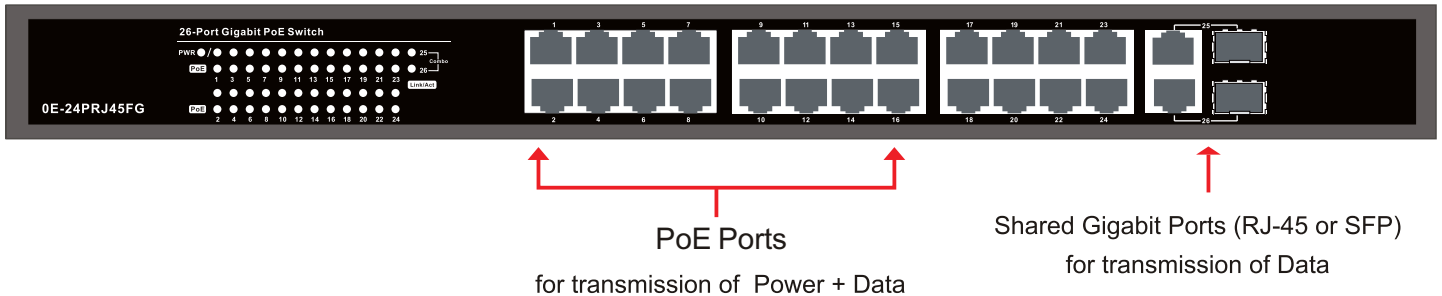

Back

