


RF Transmitters Pendant or Handheld

- 0E-2C2BPTRAN
- 0E-2C2BHTRAN
- 0E-4C4BHTRAN

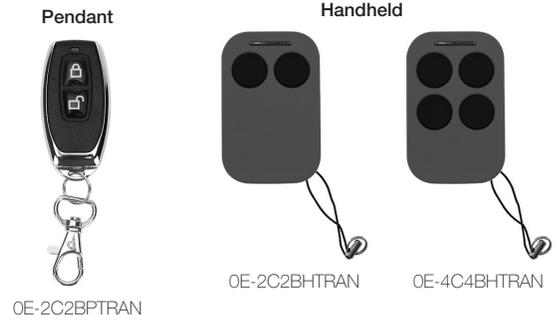

These RF transmitters enable secure wireless operation of garage doors, lights, control boxes and other essential security or access devices. The transmitters generate a unique code for each use (up to 68 million rolling codes) and offer wide compatibility with 315MHz RF receivers, such as our W Box models.

- ANTI-HACK, SECURE WIRELESS SIGNAL
- ROLLING CODE
- WIDE COMPATIBILITY WITH 315MHZ RF RECEIVERS
- STRONG SIGNAL REACHES UP TO 394 FT. (120M) FOR HANDHELD MODELS, UP TO 328 FT. (100M) FOR PENDANT MODEL
- PUSH BUTTON CONTROLS PROVIDE EASY SET-UP AND OPERATION
- LED INDICATES COMMAND SENT OR BATTERY LOW
- HANDHELD MODELS INCLUDE METAL CLIP; EASILY ATTACH TO SUN VISOR OR TOOL BAG

PART #	0E-2C2BPTRAN	0E-2C2BHTRAN	0E-4C4BHTRAN
TYPE	Pendant	Handheld	Handheld
CHANNELS	2	2	4
BUTTONS	2	2	4
RANGE	Up to 328 ft. (100m)	Up to 394 ft. (120m)	Up to 394 ft. (120m)
BATTERY	2 x 3VDC CR2016 coin Li batteries	1 x 12VDC 23A cylindrical alkaline battery	1 x 12VDC 23A cylindrical alkaline battery
SIZE	2.4" x 1.34" x 0.47"	2.28" x 1.50" x 0.49"	2.28" x 1.50" x 0.49"

FREQUENCY: 315MHz, Rolling Code

WARRANTY: 1 Year

W Box RF Receivers

Guaranteed Compatibility with W Box Transmitters

0E-1CHRFRVCVR

CHANNELS: 1

FREQUENCY: 315MHz

RANGE: Up to 394 ft. (120m)



0E-2CHRFRVCVR

CHANNELS: 2

FREQUENCY: 315MHz

RANGE: Up to 394 ft. (120m)



Product Certification:

FC IC CE RoHS



FOR MORE INFORMATION,
CONTACT YOUR ADI SALES PERSON.

Émetteurs RF suspendu ou portatif


0E-2C2BPTRAN
0E-2C2BHTRAN
0E-4C4BHTRAN

Suspendu




0E-2C2BPTRAN

Portatif

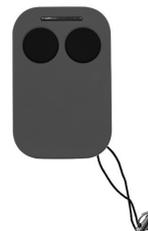

0E-2C2BHTRAN

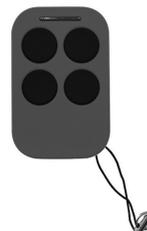

0E-4C4BHTRAN

Ces émetteurs RF permettent un commandement sans fil sécuritaire des portes de garage, des systèmes d'éclairage, des boîtes de commande et des autres appareils de sécurité ou de contrôle d'accès. Les émetteurs peuvent générer un code unique pour chaque utilisation (jusqu'à 68 millions de codes tournants) et offrent une vaste compatibilité avec les récepteurs RF 315 MHz, notamment les modèles W-Box.

- PROTECTION ANTIPIRATAGE, SIGNAL SANS FIL SÉCURISÉ
- CODE TOURNANT
- VASTE COMPATIBILITÉ AVEC LES RÉCEPTEURS RF 315 MHz
- SIGNAL PUISSANT POUVANT PARCOURIR JUSQU'À 394 PI (120 M) POUR LES MODÈLES PORTATIFS, JUSQU'À 328 PI (100 M) POUR LES MODÈLES SUSPENDUS
- BOUTONS-POUSOIRS FACILITANT LA CONFIGURATION ET L'UTILISATION
- INDICATEURS DEL DE COMMANDE ENVOYÉE ET DE PILE FAIBLE
- LES MODÈLES PORTATIFS COMPRENNENT UNE PINCE MÉTALLIQUE POUR UNE FIXATION FACILE À UNE CASQUETTE OU À UN SAC POUR ÉQUIPEMENT

No de PIÈCE	0E-2C2BPTRAN	0E-2C2BHTRAN	0E-4C4BHTRAN
TYPE	Suspendu	Portatif	Portatif
CANAUX	2	2	4
BOUTONS	2	2	4
PORTÉE	Jusqu'à 328 pi (100m)	Jusqu'à 394 pi (120m)	Jusqu'à 394 pi (120m)
PILE	2 piles boutons 3VCC CR2016 au lithium	1 pile cylindrique 12VCC 23A alcaline	1 pile cylindrique 12VCC 23A alcaline
TAILLE	2,4 x 1,34 x 0,47 po	2,28 x 1,50 x 0,49 po	2,28 x 1,50 x 0,49 po

FRÉQUENCE: 315MHz, Code tournant

GARANTIE: 1 an

Récepteurs W Box

Garantie de compatibilité avec les émetteurs W Box

0E-1CHRFRVCVR

CANAUX: 1

FRÉQUENCE: 315MHz

PORTÉE: Jusqu'à 394 pi (120m)



0E-2CHRFRVCVR

CANAUX: 2

FRÉQUENCE: 315MHz

PORTÉE: Jusqu'à 394 pi (120m)



Certification du produit:

FC IC CE RoHS



POUR PLUS DE DÉTAILS, COMMUNIQUEZ AVEC VOTRE REPRÉSENTANT COMMERCIAL ADI.

fr.adiglobaldistribution.ca