


## FULL HD PRO-GRADE LED COLOR MONITOR

24/7/365 Operating Capability

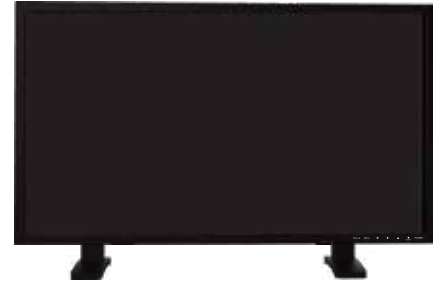

This professional-grade widescreen LED 31.5" color monitor offers HDMI, VGA and BNC inputs. With the BNC looping output, its versatility will allow it to work for any application. Boasting 16.7 million colors and FHD resolution, this monitor will make your video come to life.


### FEATURES

- 31.5" Diagonal Viewing Size
- 1920x1080P Full HD Resolution
- VGA, BNC and HDMI Inputs
- IPS Technology, 178° Viewing Angle
- Source Auto Detection
- Quick Touch Scalability 16:9/4:3
- Includes Audio, VGA, HDMI and Power Cables
- 30-Month Warranty
- PART #: 0E-32LEDMON2
- UPC: 811914029809
- LENGTH: 29"
- WIDTH: 6.3"
- HEIGHT: 20.3"
- WEIGHT: 22.9 lbs.
- UL LISTING



## MONITEUR COULEUR HD INTÉGRALE À DEL DE QUALITÉ PROFESSIONNELLE

Capacité de fonctionnement 24/7/365

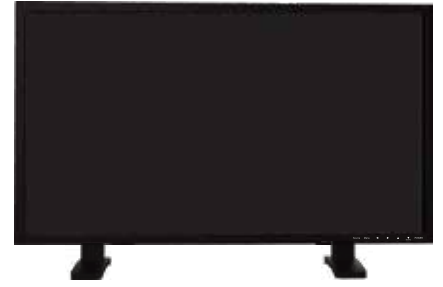

Ce moniteur couleur de 31,5 po à DEL de qualité professionnelle est doté d'entrées HDMI, VGA et BNC. Grâce à sa sortie BNC à bouclage supplémentaire qui lui procure une polyvalence accrue, ce moniteur fonctionnera pour de nombreuses applications. Avec ses 16,7 millions de couleurs et sa résolution FHD, ce moniteur vous permettra de visionner des vidéos de qualité inégalée.

### CARACTÉRISTIQUES

- Dimensions d'axe diagonales de 31,5 po
- Résolution Full HD 1920x1080 p
- Entrées VGA, BNC et HDMI
- Technologie IPS - angle de vue de 178°
- Détection automatique de la source
- Mise à l'échelle Quick Touch 16:9/4:3
- Comprend des câbles audio, VGA, HDMI et d'alimentation
- Garantie de 30 mois
- N° de pièce : 0E-32LEDMON2
- UPC : 811914029809
- Longueur : 29 po
- Largeur : 6,3 po
- Hauteur : 20,3 po
- Poids : 22,9 lb
- Homologué UL



Model	OE-32LEDMON2
Screen Diagonal Dimension (inches)	31.5"
Viewable Area W x H (inches)	27.5" x 15.47"
Led Type	Edge LED
Pixel Pitch (mm)	0.36mm x 0.36mm
Screen Maximum Resolution	1920x1080
Display Resolutions	640x480; 800x600; 1024x768; 1280x1024; 1920x1080
Supported Input Resolutions	640x480; 800x600; 1024x768; 1280x1024; 1920x1080
Refresh Rate (hertz)	60Hz
Color Depth (millions)	16.7 million colors
Brightness (cd/m <sup>2</sup> )	300 cd/m <sup>2</sup>
Auto Adjust	Yes
Monitor Aspect Ratio	16:9
Display Aspect Ratio	OSD selectable 16:9 or 4:3
Horizontal TV Lines	1080
Contrast Ratio	3000 :1SCR
Response Time (ms)	5 ms (GTG)
View Angle H/V (degrees)	178°x 178°/CR>10
Digital Video Inputs	HDMI up to 1920 x1080
Analog Video In/Out	VGA up to 1920x1080, BNC CVBS looping
Audio Inputs (stereo)	1x3.5mm mini-jack
Speakers (watts)	2 x 5 watts
Stand-by (watts)	<0.5 watts
Power Consumption (watts)	50W watts typical
Monitor Body Dimensions (inches)	29" x 2.1" x 17.4"
Dimensions Monitor+Stand (inches)	29" x 6.3" x 20.3"
Panel Surface	Matte black
Case and Stand Material	Metal + Aluminum (removable stand)
VESA Mounting Pattern (mm)	200mm x 200mm
Base/Stand Included	Yes
Base Tilt Angle	-5°-15°
Weight Cabinet Only (lbs.)	21.1 lbs.
Weight Cabinet+Base Stand (lbs.)	22.9 lbs.
Power Supply (internal)	AC 100-240V-50/60Hz 1.1A
Operating Temperature	0°C-40°C / 32°F-104°F
Storage Temperature	-20°C-50°C / -4°F-122°F
Operating Humidity	10-90%
Accessories Included in the Box	Power cable/HDMI cable/VGA cable/Audio cable/IR Remote/Batteries Allen wrench/Screws/Base of stand/Stand support/User manuals
Rack Mount Screw Size (mm)	Screws for Mounting Monitor, Screws Type: HMØ6.0x10mm/4pcs Screws for Securing Base of Stand, Screws Type: KMØ4.0x10mm/6pcs Screws for Installing Monitor Stand, Screws Type: HMØ6.0x10mm/4pcs
Certifications	CE/FCC/RoHS/HDMI/UL/WEEE/REACH
Warranty	30 Months

**FOR MORE INFORMATION, CONTACT YOUR ADI SALES PERSON.**