



HDMI EXTENDER OVER SINGLE UTP

0E-HDMIEX2K



0E-HDMIEX2K HAS CAPABILITIES TO TRANSMIT FULL 1080P HD VIDEO, HD AUDIO AND IR CONTROL SIGNAL UP TO 164FT.

SPECIFICATIONS:

Technical

- Input: 1 x HDMI IN
- Output: 1 x HDMI OUT
- Input/Output Signal Type:
HDMI 1.3b, HDCP 1.4
- Resolution Supported:
Up to 1080@60Hz, including 1080P/1080I/720P/720I
- Maximum Data Rate: 4.45Gbps
- Maximum Pixel Clock: 148MHz
- Transmission Distance:
Cat 5e cable - 1080P@60Hz: up to 40m/131ft.
Cat 6/6a/7 cable - 1080P@60Hz: up to 50m/164ft.
Note: T568B straight-through category cables are recommended to use.
- Warranty: 2 years


- PART#: 0E-HDMIEX2K
- UPC: 840049302426

General

- Operating Temperature:
0°C to 45°C (32°F to 113°F)
- Storage Temperature:
-20°C to 70°C (-4°F to 158°F)
- Humidity:
10% to 90%, non-condensing
- ESD Protection:
±8kV (Air-gap discharge)/
±4kV (Contact discharge)
- Surge Protection: Voltage: ±1 kV
- Power Supply: DC 5V 1A
- Power Consumption (max): 2.5W (Pair, PoC)
- Device Dimension (Transmitter / Receiver):
7.0cm x 2.0cm x 7.02cm/2.76" x 0.79" x 2.76"
- Product Weight (Transmitter/Receiver): 0.2kg/0.44lb

For more information please call 1-833-574-9124
or email AVARRO@adiglobal.com

To learn more about AVARRO products visit
avarro.adiglobaldistribution.us

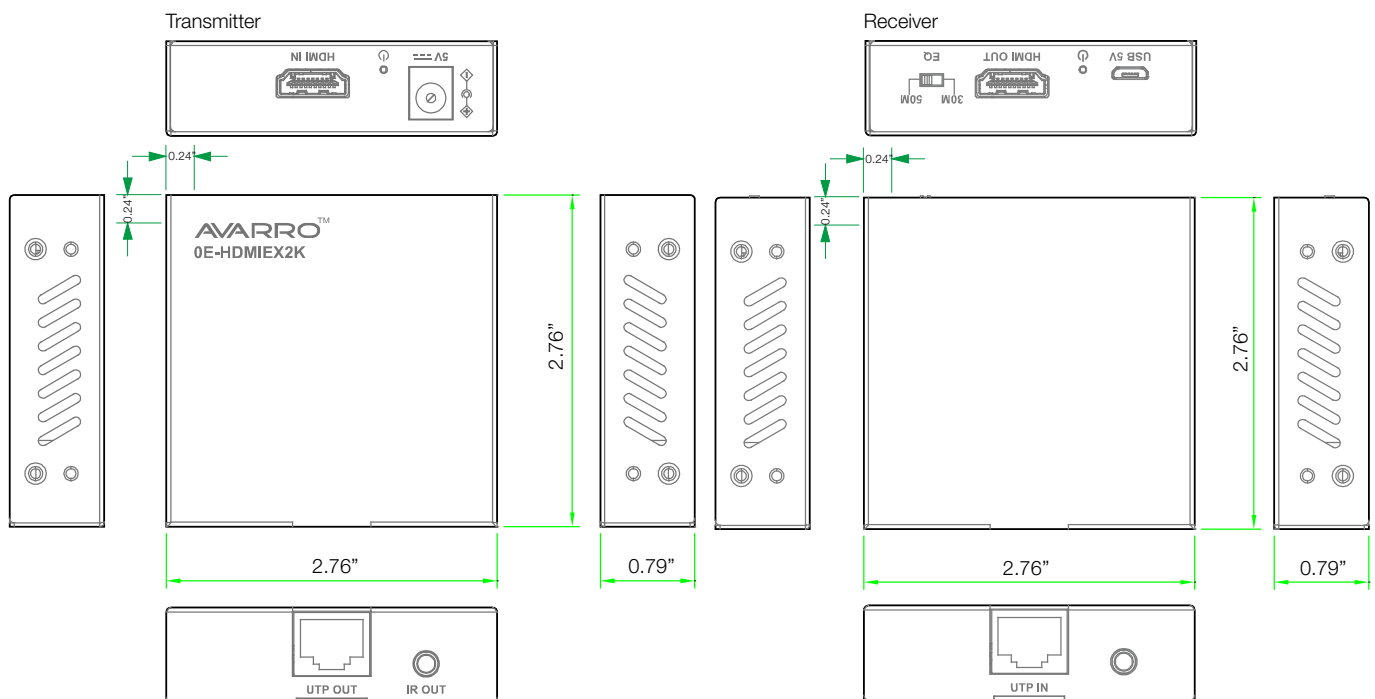

For more information please call 1-833-574-9124
or email AVARRO@adiglobal.com

To learn more about AVARRO products visit
avarro.adiglobaldistribution.us