



HDMI SWITCHER

4 INPUTS X 4 OUTPUTS

OE-HDMIMX4

SUPPORTS RESOLUTIONS UP TO 4K@60 4:4:4 8BIT WITH HDR AND HDCP 2.2 COMPATIBILITY. FEATURES 4K-1080P DOWNSCALER, RS232 CONTROL, IR CONTROL AND WEB UI CONTROL.

SPECIFICATIONS:

Technical

- Input/Output Port:
4 x HDMI IN, 4 x HDMI OUT, 1 x RS232, 1 x IP CONTROL (RJ45),
4 x SPDIF OUT (Digital), 1 x FW (Micro USB), 1 x DC 12V IN
- Resolution Supported:
VESA:
800x600⁸, 1024x768⁸, 1280x768⁸, 1280x800⁸, 1280x960⁸,
1280x1024⁸, 1360x768⁸, 1366x768⁸, 1440x900⁸, 1600x900⁸,
1600x1200⁸, 1680x1050⁸, 1920x1200⁸
SMPT:
720x576P⁶, 1280x720P^{6,7,8}, 1920x1080P^{2,5,6,7,8}, 3840x2160^{2,3,5,6,8},
4096x2160^{2,3,5,6,8}
(1 = at 23.98 Hz, 2 = at 24 Hz, 3 = at 25 Hz, 4 = at 29.97 Hz,
5 = at 30 Hz, 6 = at 50 Hz, 7 = at 59.94 Hz, 8 = at 60 Hz,
9 = at 75 Hz)
- Maximum Data Rate: 18Gbps
- Maximum Pixel Clock: 600MHz
- Audio Format:
HDMI IN/OUT: Fully supports audio formats in HDMI 2.0
specification, including PCM 2.0/5.1/7.1, Dolby TrueHD, Dolby
Atmos, DTS HD Master Audio and DTS:X
S/PDIF OUT: Supports PCM 2.0/5.1, Dolby digital and DTS up to 5.1
Channel
- Warranty: 2 years


- PART#: OE-HDMIMX4
- UPC: 840049305786

General

- Operating Temperature:
0°C to 45°C (32°F to 113°F)
- Storage Temperature:
-20°C to 70°C (-4°F to 158°F)
- Humidity:
10% to 90%, non-condensing
- ESD Protection:
±8kV (Air-gap discharge)/
±4kV (Contact discharge)
- Surge Protection: Voltage: ±1 kV
- Power Supply: DC 12V 2A
- Power Consumption (max): 10.8W
- Device Dimension:
21.5cm x 4.2cm x 12.02cm/8.46" x 1.65" x 4.73"
- Product Weight: 0.54kg/1.19lbs

For more information please call 1-833-574-9124
or email AVARRO@adiglobal.com

To learn more about AVARRO products visit
avarro.adiglobaldistribution.us

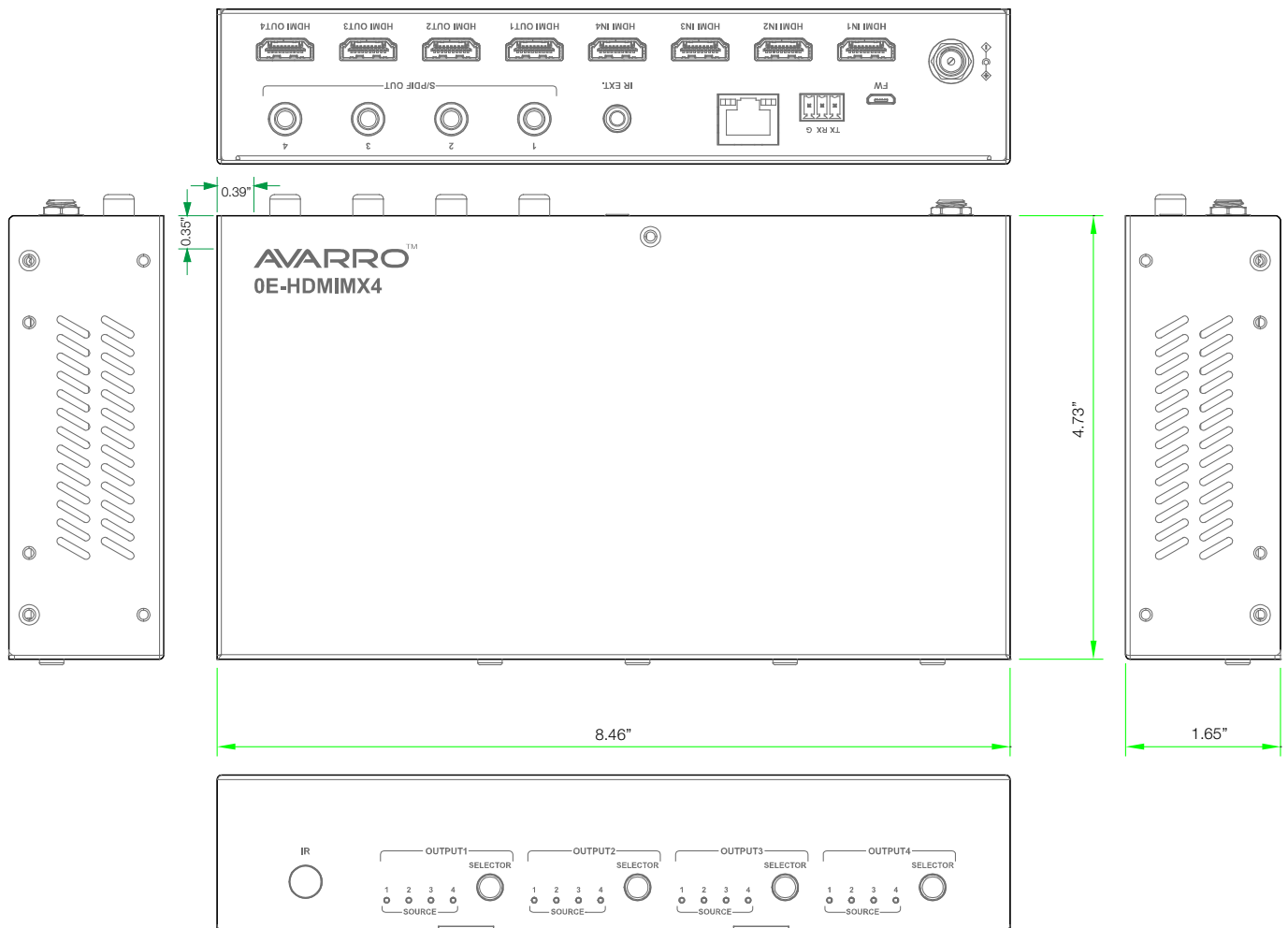

For more information please call 1-833-574-9124
or email AVARRO@adiglobal.com

To learn more about AVARRO products visit
avarro.adiglobaldistribution.us