

AVARRO™

HDMI SPLITTER 4 PORTS WITH SCALER

0E-HDMISP4



0E-HDMISP4 IS A 1:4 SPLITTER FOR HDMI WITH ULTRA HD 4K SUPPORT THAT RELIABLY DISTRIBUTES ONE HDMI SOURCE SIGNAL TO FOUR HDMI OUTPUTS.

SPECIFICATIONS:

Technical

- Input/Output: 1 x HDMI IN; 4 x HDMI OUT
- Input/Output Signal Type: HDMI with HDCP 2.2, HDR, 3D, Scaler
- Resolution Supported:
Up to 4096x2160@60Hz, including 4K@60Hz
/4K@30Hz/1080P/1080i/720P
- Maximum Data Rate: 18 Gbps
- Maximum Pixel Clock: 600 MHz
- Audio Format:
Fully supports audio formats in HDMI 2.0 specification, including PCM, Dolby TrueHD, Dolby Atmos, DTS-HD Master Audio, DTS:X; S/PDIF: PCM 2.0, Dolby Digital, DTS 5.1
- Warranty: 2 years


- PART#: 0E-HDMISP4
- UPC: 840049302464

General

- Operating Temperature:
0°C to 45°C (32°F to 113°F)
- Storage Temperature:
-20°C to 70°C (-4°F to 158°F)
- Humidity:
10% to 90%, non-condensing
- ESD Protection:
±8kV (Air-gap discharge)/
±4kV (Contact discharge)
- Surge Protection: Voltage: ±1 kV
- Power Supply: DC 5V 1A
- Power Consumption (max): 1.8W
- Device Dimension:
14.0cm x 2.0cm x 6.52cm /5.51" x 0.79" x 2.57"
- Product Weight: 0.24kg/0.53lb

For more information please call 1-833-574-9124
or email AVARRO@adiglobal.com

To learn more about AVARRO products visit
avarro.adiglobaldistribution.us

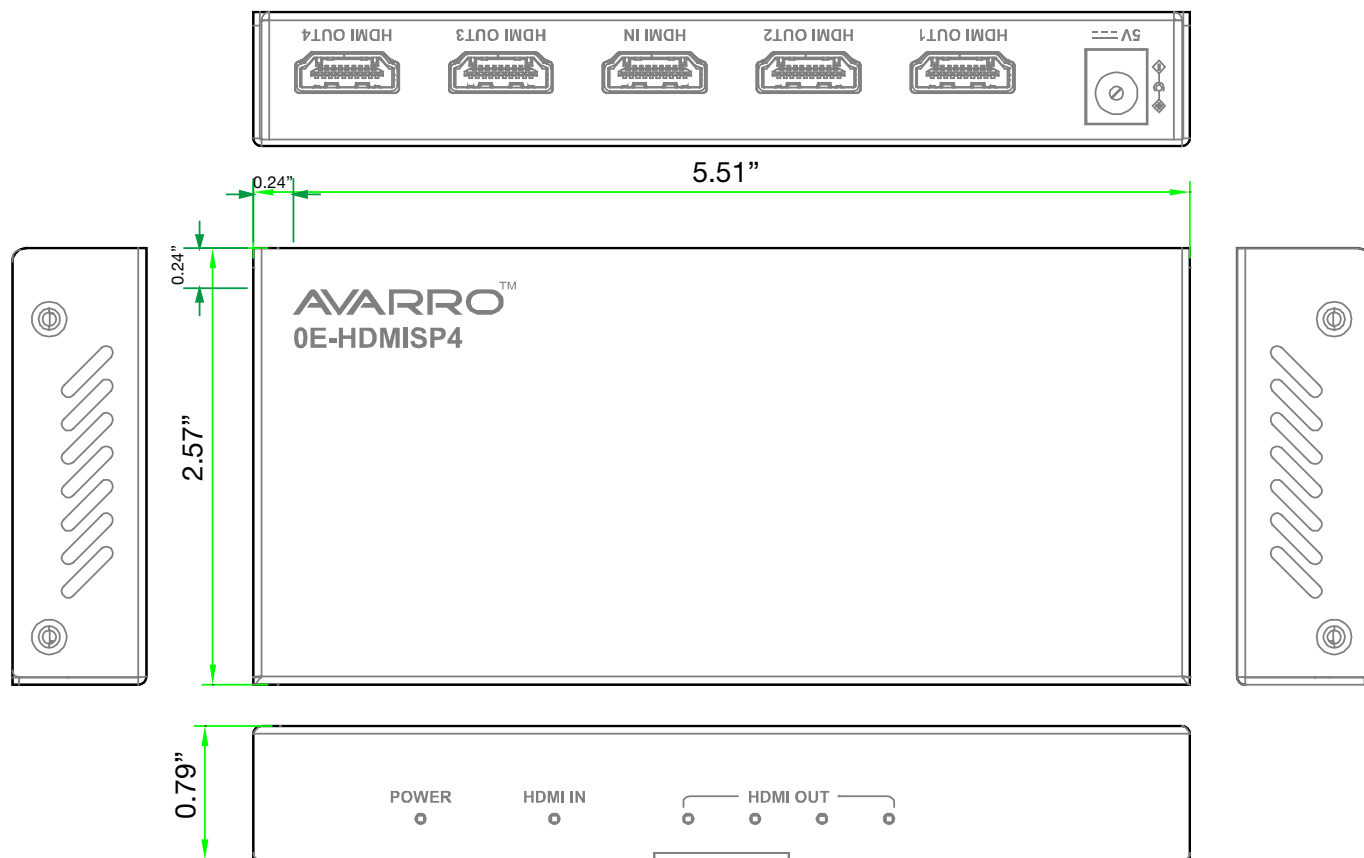

For more information please call 1-833-574-9124
or email AVARRO@adiglobal.com

To learn more about AVARRO products visit
avarro.adiglobaldistribution.us