




10 FT ULTRA SLIM HDMI® CABLE

OE-SLIM10

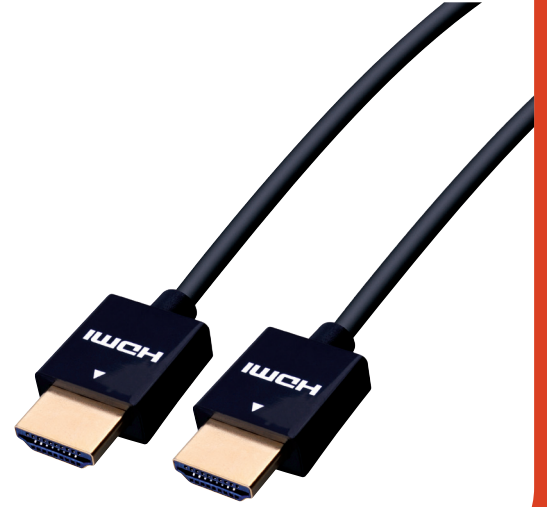

SPECIFICATIONS:

- Supports 1080p @ 60Hz and 4K @ 30Hz Video Resolutions
- Data Speed Transfer: Exceeds 10.2 Gbps
- Enables IP-based applications over HDMI
- Allows 3D over HDMI when connected to 3D Devices
- Audio return channel
- UL Listed - CL3 Rated
- Limited Lifetime Warranty

PART#: OE-SLIM10
UPC: 840049302150
LENGTH: 10 FT
WEIGHT: .20 LBS

CABLE CONSTRUCTION	34 AWG
JACKET OUTER DIMENSION	4.2 MM
MINIMUM BEND RADIUS	20 MM
MAXIMUM COLOR DEPTH	48-BIT, 16 BITS PER COLOR
MAXIMUM REFRESH RATE	4K 30 HZ
HDMI HIGH SPEED	YES
ETHERNET	YES
AUDIO RETURN CHANNEL	YES
DEEP COLOR SUPPORT	YES
3D COMPATIBLE	YES
4K SUPPORT	YES
AUDIO SUPPORT	DTS-HS DOLBY TRUEHD, ATMOS

For more information please call 1-833-574-9124
or email AVARRO@adiglobal.com

To learn more about AVARRO products visit
avarro.adiglobaldistribution.us

