


UNIVERSAL ELECTRIC STRIKE FOR CYLINDRICAL LOCKSETS

0E-UNISTRIKE

This low profile Universal Electric Strike offers the best quality and performance, with an ANSI square faceplate included. This design delivers unparalleled flexibility, with field selectable voltage, fail safe/fail secure operation and mechanical adjustment of the strike body.

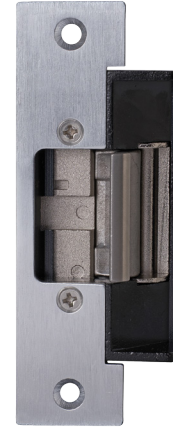

- Centerline latch entry for cylindrical, 1/2" to 5/8" latch projection
- Horizontal adjustment of strike body and faceplate
- Low profile strike body
- Selectable Fail Safe / Fail Secure
- Door Frame Types - Wood, Hollow Metal, Aluminum Frame
- 5 year warranty
- Stainless Steel ANSI Square Faceplate Included
- Performance Levels:
 - Destructive Attack: Level I
 - Standby Power: Level I
 - Line Security: Level II
 - Endurance: Level IV

- Product Certification:



PART #: **0E-UNISTRIKE**
UPC: **840049306363**

Voltage: 12/24V, AC/DC
Current Draw: 300mA @ 12 VDC,
150mA @ 24 VDC
Torque Resistance: 50 ft. lbs.
Hold Force: 1,000 lb.
Endurance: Grade 2 - 700,000 cycles
(Factory Tested)
Operation: AC - Buzz, DC - Silent
Duty: Continuous
Mounting: Non-handed
Dimensions: 3-3/8"H x 1-7/8" W x 1-7/32"D
(86mm x 44mm x 31mm)