

RG59 SIAMESE COAXIAL CABLE NON-PLENUM



95% CCA Braid+18/2 BC

Certification


Ratings CM, CL3, Sunlight Resistant
Approvals ETL Listed

Construction

Conductor 20 AWG Solid Bare Copper
Insulation Foam PE
Braid Shield CCA
Power Cord 2/18 AWG Bare Copper
Jacket PVC
Overall Diameter 0.240" nom.
Print Legend RG59 SIAMESE CM 20 AWG BARE COPPER 95%
CCA BRAID VERIFIED TO c(ETL)us #3180662

Properties

Temperature -20°C to 75°C
RoHS Compliant Yes
Impedance 75±3 Ohms
Return Loss 20dB Max. 5-1000MHz
Velocity of Propagation 83% nominal
DC Resistance 34.5 Ohms/km max. @ 20°C
Capacitance 51±3 pF/m max. @ 20°C

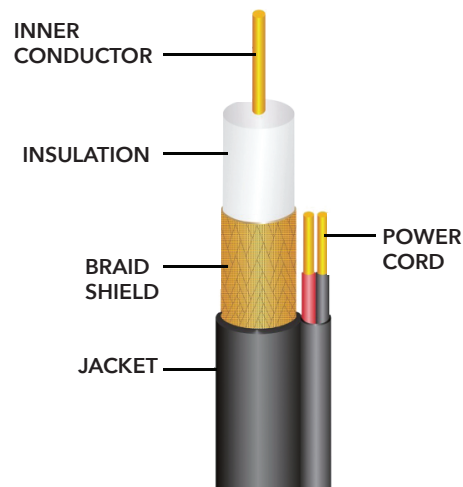

Frequency (MHz)	Return Loss Minimum (dB/100 FT)
5	0.69*
55	2.57
100	3.51
211	5.20
250	5.69
270	5.91
300	6.25
330	6.58
350	6.78
400	7.27
450	7.75
500	8.20
550	8.63
600	9.23
750	10.37
870	11.00
1000	11.83

*FOR REFERENCE ONLY

PART#	COLOR	LENGTH	BOX
RN-7000501	White	500 ft.	Reel In Box
RN-7000508	Black	500 ft.	Reel In Box



For more information contact
your ADI Sales person or visit
adiglobal.com/adiexclusivebrands