 



Air solenoid valve MFH-5-PK-3-L

FESTO

Part number: 11546

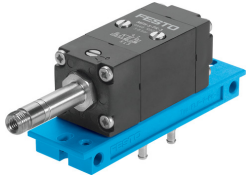

Data sheet

Feature	Value
Valve function	5/2, monostable
Standard nominal flow rate	105 l/min
Pneumatic working port	PK-3
Operating pressure	1.5 bar ... 8 bar
Structural design	Plate seat
Nominal width	2.5 mm
Type code	MFH
Sealing principle	Soft
Symbol	00991049
Switching time off	22 ms
On switching time	14 ms
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-]
Temperature of medium	-10 °C ... 60 °C
Ambient temperature	-5 °C ... 40 °C
Product weight	270 g
Type of mounting	Optionally: On sub-base On mounting frame With through-hole
Pneumatic connection 1	PK-3
Pneumatic connection 2	PK-3
Pneumatic connection 3	PK-3
Pneumatic connection 4	PK-3
Pneumatic connection 5	PK-3
Note on materials	RoHS-compliant
Material of sub-base	Aluminum Anodized
Seals material	NBR
Housing material	Aluminum Anodized