


Non return valve H-1/4-B

Part number: 11689

FESTO

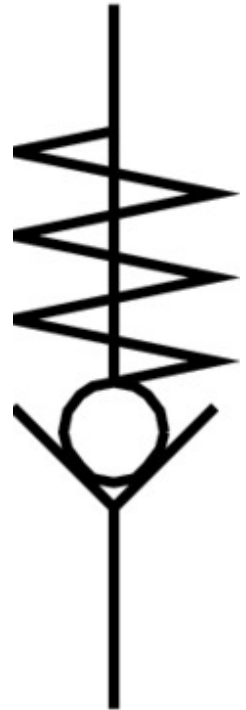

Data sheet

Feature	Value
Type code	H
Valve function	Non-return function
Pneumatic connection 1	G1/4
Pneumatic connection 2	G1/4
Type of mounting	Screw-in
Operating pressure	0.04 MPa ... 1.2 MPa
Operating pressure	0.4 bar ... 12 bar
Ambient temperature	-10 °C ... 60 °C
Housing material	Wrought aluminum alloy Anodized
Operating medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Mounting position	Any
Symbol	00991455
Standard nominal flow rate 1->2 (6-5)	1000 l/min
Information on operating and pilot media	Operation with oil lubrication possible (required for further use)
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
LABS conformity	VDMA24364-B2-L
Temperature of medium	-10 °C ... 60 °C
Pilot medium	Compressed air as per ISO 8573-1:2010 [7:4:4]
Max. tightening torque	11 Nm

Feature	Value
Product weight	25.4 g
Note on materials	Free of copper and PTFE RoHS-compliant
Seals material	NBR