


Pneumatic shock absorber YSRW-DGC-40/50-B

Part number: 1232870

FESTO

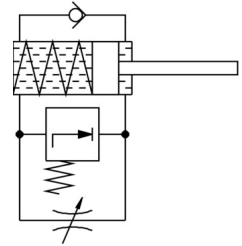

Data sheet

Feature	Value
Size	40 50
Type code	YSRW-DGC
Cushioning	Self-adjusting Soft characteristic curve
Mounting position	Any
Position sensing	None
Symbol	00991497
Max. impact velocity	3 m/s
Mode of operation	Single-acting Pushing
Corrosion resistance class (CRC)	2 - Moderate corrosion stress
Ambient temperature	-10 °C ... 80 °C
Type of mounting	With lock nut
Note on materials	Free of copper and PTFE RoHS-compliant
Piston rod material	High-alloy steel