


Sub-base VABS-C8-12XB-QX-D

Part number: 1236029

FESTO

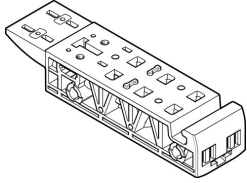

Data sheet

Feature	Value
Width	24 mm
Type code	VABS
Max. no. of valve positions	1
Corrosion resistance class (CRC)	0 - No corrosion stress
Max. tightening torque for valve mounting	0.48 Nm ... 0.72 Nm
Max. tightening torque for wall mounting	1.3 Nm
Product weight	30 g
Pilot air port 12/14	Prepared for cartridge
Pneumatic connection 1	Prepared for cartridge
Pneumatic connection 3	Prepared for cartridge
Pneumatic connection 5	Prepared for cartridge
Note on materials	Free of copper and PTFE RoHS-compliant
Manifold rail material	PA-reinforced