


Cartridge QSPKG20-1/2-U

Part number: 132638

FESTO

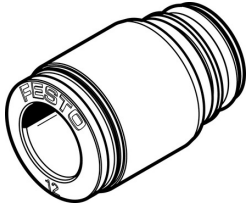

Data sheet

| Feature | Value |
|---|---|
| Size | Standard |
| Nominal width | 8.5 mm |
| Type code | QSPKG |
| Mounting position | Any |
| Pack size | 10 |
| Structural design | Push-pull principle |
| Operating pressure for entire temperature range | -0.95 bar ... 10 bar |
| Maritime classification | See certificate |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:-:-] |
| Information on operating and pilot media | Operation with oil lubrication possible |
| Corrosion resistance class (CRC) | 1 - Low corrosion stress |
| Ambient temperature | -5 °C ... 60 °C |
| Product weight | 13 g |
| Pneumatic connection 1 | QSP...20 |
| Pneumatic connection 2 | for pneumatic tubing outside diameter 1/2" |
| Releasing ring color | Gray |
| Note on materials | RoHS-compliant |
| Housing material | PA-reinforced |
| Releasing ring material | POM |
| Material of tubing seal | NBR |
| Material of tube retaining claw | High-alloy stainless steel |