


Clamping module EV-20/75-5

Part number: 13291

FESTO

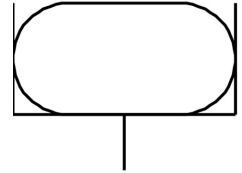

Data sheet

| Feature | Value |
|----------------------|---|
| Stroke | 5 mm |
| Clamping area | 20x75 |
| Type code | EV |
| Mounting position | Any |
| Mode of operation | Single-acting |
| Symbol | 00991208 |
| Operating pressure | 2 bar ... 6 bar |
| Operating medium | Compressed air as per ISO 8573-1:2010 [7:-:-] |
| Ambient temperature | -20 °C ... 40 °C |
| Product weight | 130 g |
| Type of mounting | With through-hole |
| Pneumatic connection | M5 |
| Note on materials | Free of copper and PTFE |
| Housing material | Die-cast aluminum |
| Diaphragm material | TPE-U(PU) |