


Plastic tubing PUN-H-2X0,4-NT

Part number: 133038

FESTO

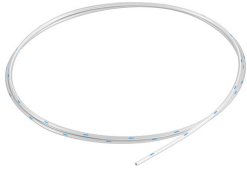

Data sheet

Feature	Value
Outside diameter	2 mm
Bending radius relevant for flow rate	8 mm
Inside diameter	1.2 mm
Min. bending radius	5 mm
Type code	PUN-H
Tubing characteristics	Suitable for energy chains in applications with high cycle rates
Pneumatic tubing test conditions	Suitability for energy chains: >5 million cycles as per FN 942021
Temperature-dependent operating pressure	-0.95 bar ... 6 bar
Operating medium	Compressed air as per ISO 8573-1:2010 [7::-]
Ambient temperature	-35 °C ... 60 °C
Product weight by length	0.0024 kg/m
Pneumatic connection	For plug connection outside diameter 2 mm
Color	Natural
Shore hardness	D 52 +/-3
Note on materials	Free of copper and PTFE RoHS-compliant
Material of pneumatic tubing	TPE-U(PU)