


# Push-in Y-connector QSY-8H-6-B

Part number: 133147

FESTO

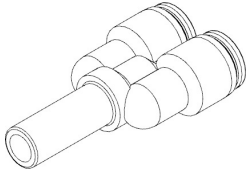

## Data sheet

Feature	Value
Size	Standard
Nominal width	3.6 mm
Type code	QSY
Mounting position	Any
Pack size	10
Structural design	Push-pull principle
Operating pressure for entire temperature range	-0.95 bar ... 6 bar
Temperature-dependent operating pressure	-0.95 bar ... 14 bar
Maritime classification	See certificate
Operating medium	Compressed air as per ISO 8573-1:2010 [7:-:-] Water as per manufacturer's declaration at <a href="http://www.festo.com">www.festo.com</a>
Information on operating and pilot media	Operation with oil lubrication possible
Corrosion resistance class (CRC)	1 - Low corrosion stress
Ambient temperature	-10 °C ... 80 °C
Product weight	8.8 g
No. of outlets	2
No. of supply lines	1
Pneumatic connection 1	Push-in sleeve QS-8
Pneumatic connection 2	for pneumatic tubing outside diameter 6 mm
Releasing ring color	Blue
Note on materials	RoHS-compliant
Housing material	PBT
Releasing ring material	POM
Material of tubing seal	NBR
Material of tube retaining claw	High-alloy stainless steel